

MOTOR SUPPRESSOR

Varistor, 3x690VAC/7,5kW

3× 690 V AC



VDR

Wire diameter 1.5 mm²

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Ürün Linki

örnekleme

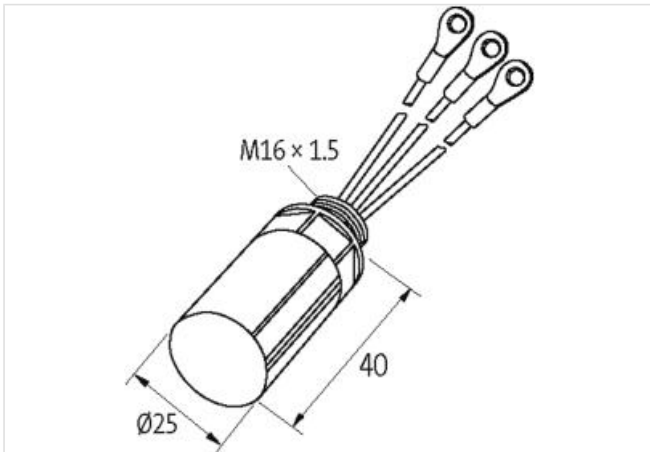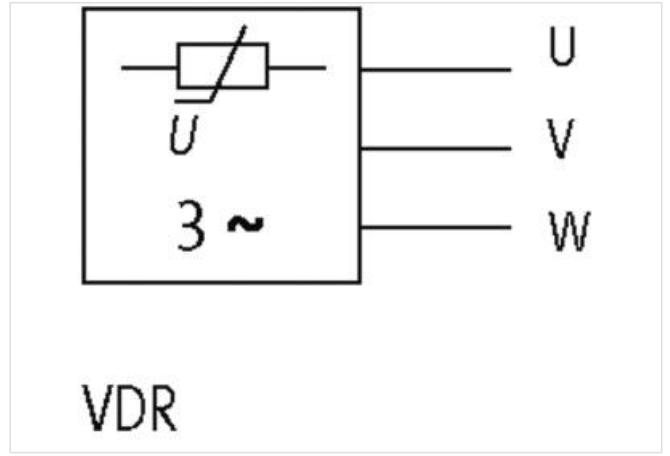

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013

ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
GTIN	4048879018890
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Electrical data Supply	
Power frequency	10 ... 400 Hz
Electrical data Input	
Input voltage AC	690 V
Installation	
Connection cross section max.	0,5 mm ²
Installation Connection	
Connection information	Single strands
Length single strands	100 mm
Ring terminals	M6isolated
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
Height	25 mm
Width	25 mm
Depth	40 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C