

**MOTOR SUPPRESSOR**

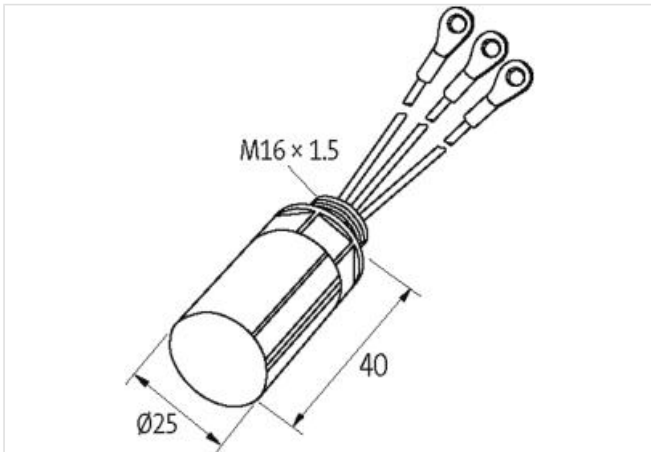
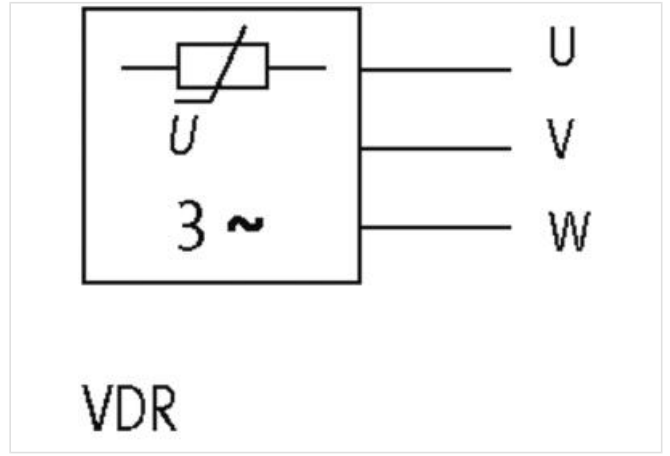
Varistor, 3x400VAC/4kW

3x 400 V AC

VDR

isolated M4

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

**Ürün Linki****örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

|            |          |
|------------|----------|
| ECLASS-6.0 | 27371013 |
| ECLASS-6.1 | 27371013 |
| ECLASS-7.0 | 27371013 |
| ECLASS-8.0 | 27371013 |
| ECLASS-9.0 | 27371013 |

|                                                 |                     |
|-------------------------------------------------|---------------------|
| ECLASS-10.1                                     | 27371013            |
| ECLASS-11.1                                     | 27371013            |
| ECLASS-12.0                                     | 27371013            |
| ETIM-5.0                                        | EC000197            |
| GTIN                                            | 4048879018883       |
| Gümrük tarife no (gtip)                         | 85363010            |
| Paket miktarı                                   | 1                   |
| <b>Electrical data   Supply</b>                 |                     |
| Power frequency                                 | 10 ... 400 Hz       |
| <b>Electrical data   Input</b>                  |                     |
| Input voltage AC                                | 400 V               |
| <b>Installation</b>                             |                     |
| Connection cross section max.                   | 0,5 mm <sup>2</sup> |
| <b>Installation   Connection</b>                |                     |
| Connection information                          | Single strands      |
| Length single strands                           | 100 mm              |
| Ring terminals                                  | M4isolated          |
| <b>Device protection   Media</b>                |                     |
| Flame resistance                                | flame retardant     |
| <b>Mechanical data   Material data</b>          |                     |
| Combustibility class housing (UL94)             | V-0                 |
| Material housing                                | Plastic             |
| Material potting compound                       | 2-component epoxy   |
| <b>Mechanical data   Mounting data</b>          |                     |
| Mounting method                                 | inserted            |
| Suitable for mounting type                      | Motorklemmkasten    |
| Height                                          | 25 mm               |
| Width                                           | 25 mm               |
| Depth                                           | 40 mm               |
| <b>Environmental characteristics   Climatic</b> |                     |
| Operating temperature min.                      | -20 °C              |
| Operating temperature max.                      | 60 °C               |