

## ABB CONTACTOR SUPPRESSOR

Varistor, 230VAC/DC



230 V AC/DC

VDR

For other configurations and voltages, please inquire.

### Ürün Linki

örnekleme

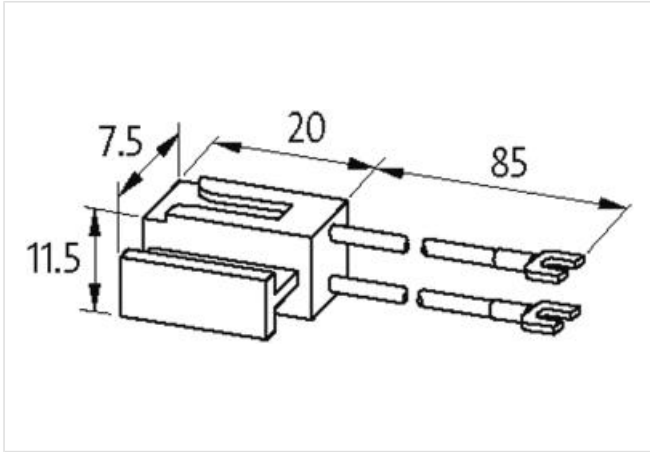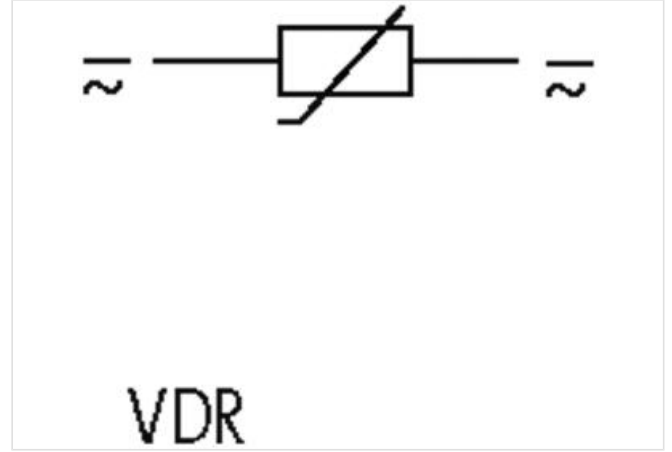

Ürün Image farklı olabilir



### Ticari bilgiler

|             |          |
|-------------|----------|
| ECLASS-6.0  | 27371013 |
| ECLASS-6.1  | 27371013 |
| ECLASS-7.0  | 27371013 |
| ECLASS-8.0  | 27371013 |
| ECLASS-9.0  | 27371013 |
| ECLASS-10.1 | 27371013 |

|                                                 |                           |
|-------------------------------------------------|---------------------------|
| ECLASS-11.1                                     | 27371013                  |
| ECLASS-12.0                                     | 27371013                  |
| ETIM-5.0                                        | EC002498                  |
| GTIN                                            | 4048879018425             |
| Gümrük tarife no (gtip)                         | 85363010                  |
| Paket miktarı                                   | 1                         |
| <b>Compatibility   Compatible with</b>          |                           |
| Appropriate contactors                          | B 6, BC 6, KC 6, VB 6     |
| <b>Electrical data</b>                          |                           |
| Damping factor                                  | 1.5× UN                   |
| <b>Electrical data   Input</b>                  |                           |
| Input voltage AC min.                           | 150 V                     |
| Input voltage AC max.                           | 250 V                     |
| Input voltage DC min.                           | 150 V                     |
| Input voltage DC max.                           | 250 V                     |
| <b>Installation   Connection</b>                |                           |
| Connection information                          | self-securing cable forks |
| <b>Device protection   Media</b>                |                           |
| Flame resistance                                | flame retardant           |
| <b>Mechanical data   Material data</b>          |                           |
| Combustibility class housing (UL94)             | V-0                       |
| Material housing                                | Plastic                   |
| <b>Mechanical data   Mounting data</b>          |                           |
| Height                                          | 20 mm                     |
| Width                                           | 11,5 mm                   |
| Depth                                           | 7,5 mm                    |
| <b>Environmental characteristics   Climatic</b> |                           |
| Operating temperature min.                      | -20 °C                    |
| Operating temperature max.                      | 70 °C                     |