

SIEMENS CONTACTOR SUPPRESSOR

Diode, 0...240VDC



24...240 V DC

Diode

For other configurations and voltages, please inquire.

Ürün Linki

örnekleme

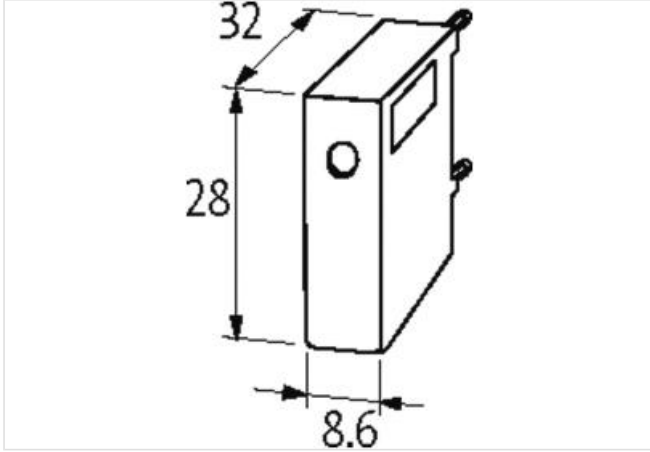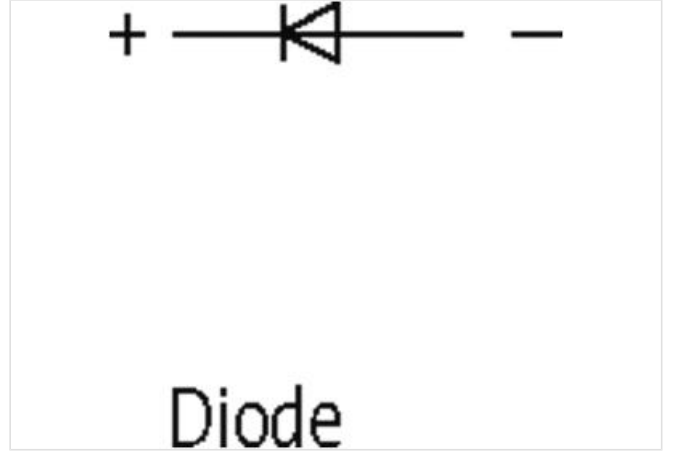

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
GTIN	4048879017640
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Compatibility Compatible with	
Appropriate contactors	3 RH 1/11; 3 RT 1/3 RH1; 3 RT 1/10.15...10.17
Electrical data Input	
Input voltage DC min.	12 V
Input voltage DC max.	240 V
Mechanical data Mounting data	
Height	28 mm
Width	8,6 mm
Depth	32 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C