

## SIEMENS CONTACTOR SUPPRESSOR

Varistor, 230VAC/DC



230 V AC/DC

VDR

For other configurations and voltages, please inquire.

### Ürün Linki

örnekleme

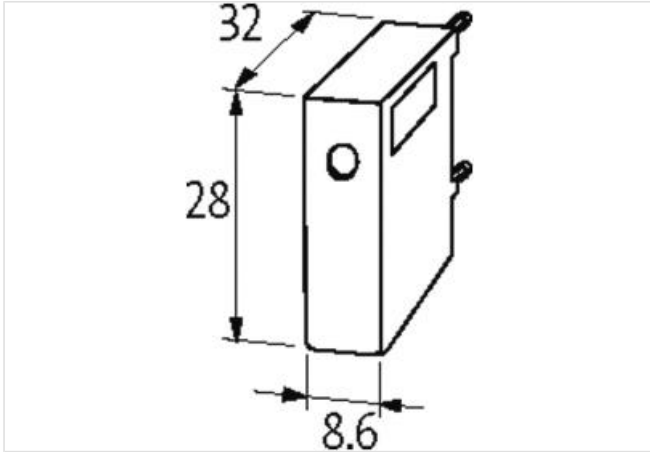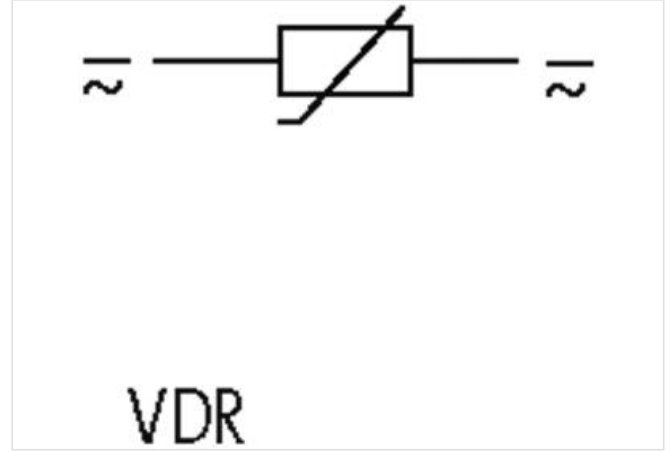

Ürün Image farklı olabilir



### Ticari bilgiler

|             |          |
|-------------|----------|
| ECLASS-6.0  | 27371013 |
| ECLASS-6.1  | 27371013 |
| ECLASS-7.0  | 27371013 |
| ECLASS-8.0  | 27371013 |
| ECLASS-9.0  | 27371013 |
| ECLASS-10.1 | 27371013 |

|                         |               |
|-------------------------|---------------|
| ECLASS-11.1             | 27371013      |
| ECLASS-12.0             | 27371013      |
| ETIM-5.0                | EC002498      |
| GTIN                    | 4048879017572 |
| Gümrük tarife no (gtip) | 85363010      |
| Paket miktarı           | 1             |

**Compatibility | Compatible with**

|                        |                                               |
|------------------------|-----------------------------------------------|
| Appropriate contactors | 3 RH 1/11; 3 RT 1/3 RH1; 3 RT 1/10.15...10.17 |
|------------------------|-----------------------------------------------|

**Electrical data | Input**

|                       |       |
|-----------------------|-------|
| Input voltage AC min. | 110 V |
| Input voltage AC max. | 253 V |
| Input voltage DC min. | 110 V |
| Input voltage DC max. | 253 V |

**Mechanical data | Mounting data**

|        |        |
|--------|--------|
| Height | 28 mm  |
| Width  | 8,6 mm |
| Depth  | 32 mm  |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C  |