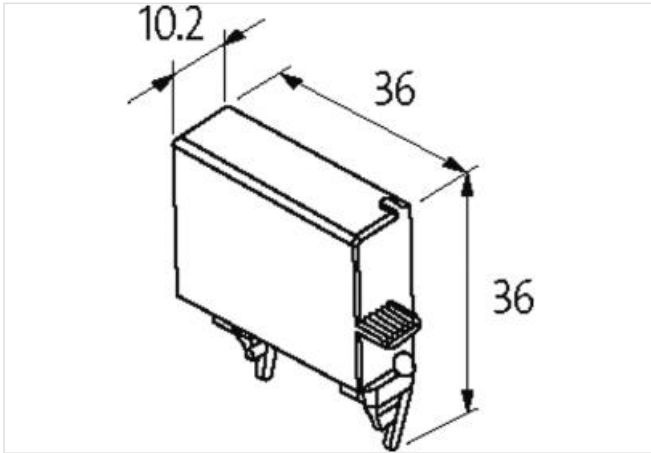
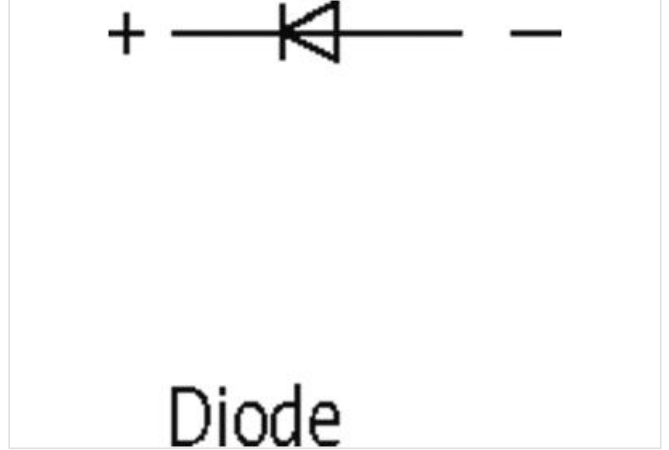


SUPPRESSOR FOR SIEMENS CONTACTOR

Diode combination, 24 VDC, 10 W

24 V AC/DC

Diode

Ürün Linki[örnekleme](#)

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013

ETIM-5.0	EC002498
GTIN	4048879017541
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Compatibility Compatible with	
Appropriate contactors	3 RT 1.3/1.4
Electrical data	
Damping factor	1.5× UN
Electrical data Input	
Input voltage DC min.	0 V
Input voltage DC max.	30 V
Installation Connection	
Connection information	Plug contact
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Height	36 mm
Width	10,2 mm
Depth	36 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C