




POWER DISTRIBUTOR PD4 7/8" 5 POLE

24+E male to 4 x 7/8" 5-pole female

 Industry male plug 24+PE
 to 4x 7/8" UNF female
 5-pole

Ürün Linki

örnekleme

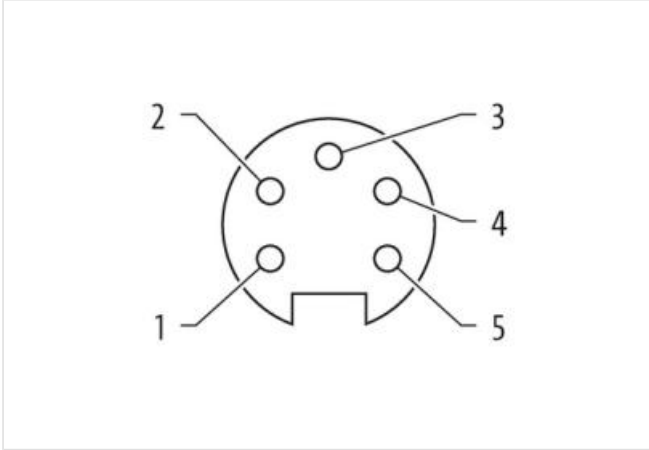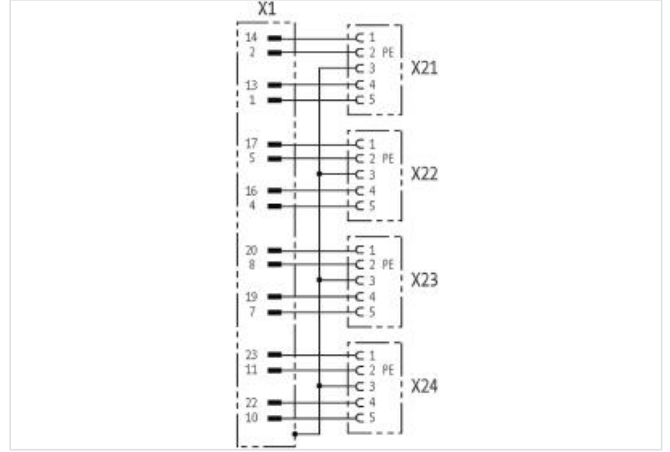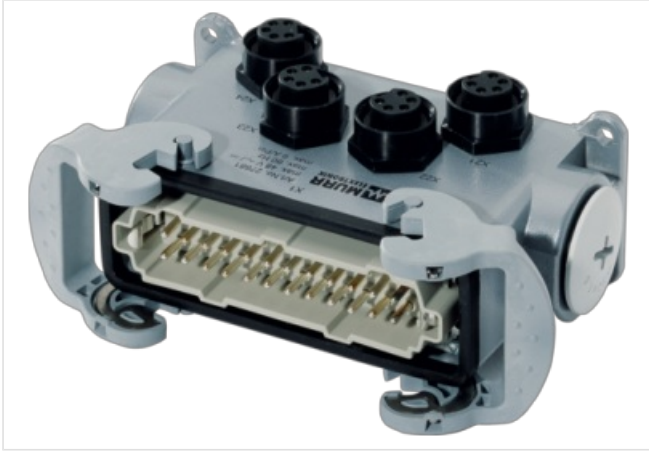

Ürün Image farklı olabilir


Ticari bilgiler

ECLASS-6.0	27279219
ECLASS-6.1	27142601
ECLASS-7.0	27142601
ECLASS-8.0	27142601
ECLASS-9.0	27142601
ECLASS-10.1	27142601

ECLASS-11.1	27142606
ECLASS-12.0	27142606
ETIM-5.0	EC002585
GTIN	4048879063449
Gümrük tarife no (gtip)	85369010
Paket miktarı	1
Electrical data	
Security level	SELV
Electrical data Supply	
Operating voltage AC	50 V
Operating voltage DC	120 V
Current operating per contact max.	9 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed
Mechanical data Material data	
Coating housing	powder-coated
Material housing	Aluminum die casting
Mechanical data Mounting data	
Height	165 mm
Width	70 mm
Depth	100 mm
Looking techniques	2-hand fixing (2 clamps)
Environmental characteristics Climatic	
Operating temperature min.	-30 °C
Operating temperature max.	85 °C