

PASSIVE-DI0° PLASTIC,8XM12.4POL,PRE-WIRED CABLE

3.0m PUR-JB 8*0,34+3*0,75

8 yollu, 4 kutuplu

PUR/PVC

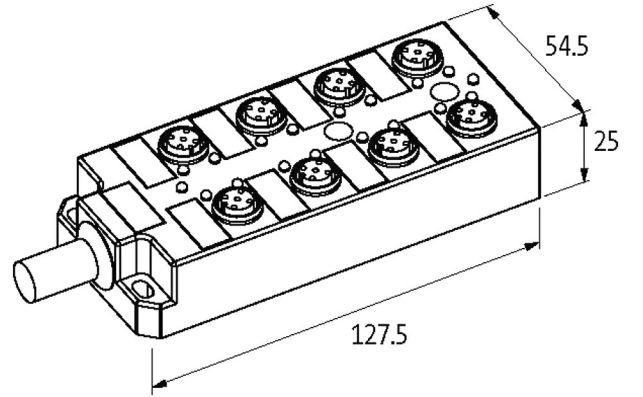
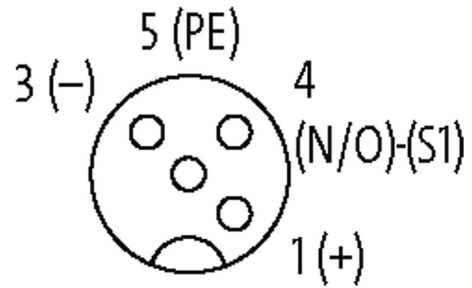
3.0 m

24 V DC PNP sinyalleri için LED'li

Farklı kablo boyları tedarik edilebilir.

Ürün Linki

örnekleme

**M12 Females 4-pole**

Ürün Image farklı olabilir

Technical Data

| | |
|------------------------------------|--|
| Operating voltage | 24 V DC |
| Signal per port | 1 - (31-32) |
| Operating current per contact | max. 4 A |
| Total current | max. 10 A |
| Locking of ports | Vida dışı (M12×1 mm) |
| General data | |
| Dimensions H×W×D | 127.5×54.5×25 mm |
| Protection | IP67 takılı ve vidalı konumda (EN 60529) |
| Temperature range | -20...+80 °C |
| Cables | |
| No./diameter of wires | 8× 0.34 + 3× 0.75 mm ² |
| Wire isolation | PVC |
| C-track properties | 2 Mio. |
| Jacket Color | gri |
| Material (jacket) | PUR/PVC (UL/CSA) |
| Outer Ø | 8.1 mm ±5% |
| Bend radius (moving) | 10× dış çap |
| Temperature range (fixed) | -30...+80 °C |
| Temperature range (mobile) | -5...+70 °C |
| Cable identification | 362 |
| Cable Type | 2 (PUR/PVC) |
| Approval (cable) | UL (AWM-Style 20549/1731), CE conform |
| Cable weight [g/m] | 115,5 |
| Material (wire) | Cu kordon, çıplak |
| Resistor (core) | max. 57 Ω/km (0.34 mm ²), max. 26 Ω/km (0.75 mm ²); (20 °C) |
| Single wire Ø (core) | 0.15 mm (0.34 mm ²); 0.2 mm (0.75 mm ²) |
| Construction (core) | 19× 0.15 mm (0.34 mm ²); 24× 0.2 mm (0.75 mm ²); (kordon sınıfı 5) |
| Diameter (core) | 8× 0.34 + 3× 0.75 mm ² |
| AWG | AWG 22 benzeri(0.34 mm ²); AWG 18 benzeri(0.75 mm ²) |
| Material (wire isolation) | PVC |
| Material property (wire isolation) | CFC, kadmiyum, silikon ve kurşun içermez |
| Shore hardness (wire isolation) | 43 ±5 D |
| Wire-Ø incl. isolation | 1.3 mm ±5% (0.34 mm ²); 1.8 mm ±5% (0.75 mm ²) |
| Color/numbering of wires | wh, vi, gn, ye, gr, pk, rd, bk+br, bl, gnye boyuna şeritli |
| Shield | hayır |
| Material (jacket) | PUR/PVC |
| Outer-Ø (jacket) | 8.1 mm ±5% |
| Color (jacket) | gri |
| chemical resistance | yağa, benzine ve kimyasallara iyi dirençli (EN 60811-404) |
| Nominal voltage | U0/U 300/300 V AC |
| Test voltage | 2000 V AC |
| Current load capacity | DIN VDE 0298-4 uyarınca |
| Temperature range (fixed) | -30...+80 °C |
| Temperature range (mobile) | -5...+70 °C |
| Bend radius (fixed) | 5× dış çap |
| Bend radius (moving) | 10× dış çap |
| No. of bending cycles (C-track) | max. 2 Mio. (25 °C) |
| Traversing distance (C-track) | max. 5 m (horizontal) |
| Travel speed (C-track) | max. 2 m/s |

Acceleration (C-track) max. 10 m/s²**Contact Layout**

PIN 1 (+)

PIN 3 (-)

PIN 4 (NO)/(S1)

PIN 5 (Toprak)

LED (yeşil): Güç / LED (sarı): (S1)

Ticari bilgiler

EAN 4048879062817

eClass 27279219

Gümrük tarife no (gtip) 85444290

Menşei CZ

Paket miktarı 1