



EMMS-30-64/1 OPTO-COUPLER MODULE


IN: 253 VDC - OUT: 53 VDC / 1,2 A

Transistör 1.2 A
110/230 V AC

Ürün Linki

örnekleme

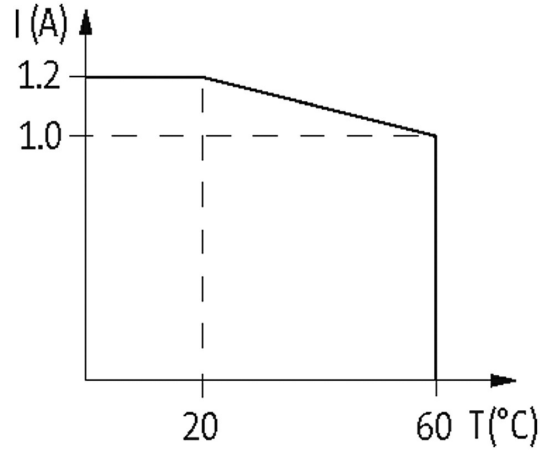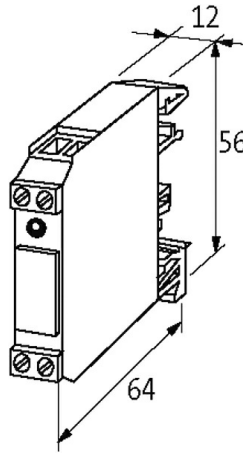

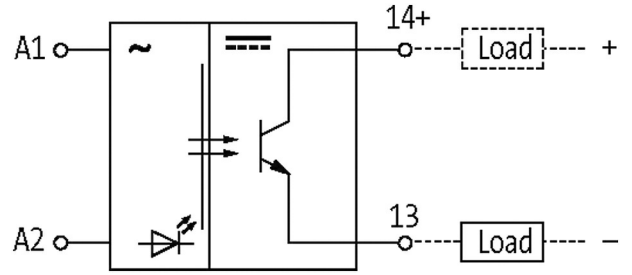

Ürün Image farklı olabilir

General data

Test isolation voltage	3.75 kV
Housing	Plastik siyah, alev geciktirici
Mounting method	TH35 veya G32 Raya Montaj (EN 60715)
Temperature range	-20...+60 °C
Dimensions H×W×D	56×12×64 mm

Output

Switching voltage	4.5...53 V DC
Switching current per output	1 mA...1.2 A
Saturation voltage (across output)	max. 1.2 V DC
Leakage current (output is open)	max. 0.3 mA
Switching time ON/OFF	20/50 ms
Switching frequency	max. 5 Hz

Input

Voltage range ON	100...253 V AC
Voltage range OFF	0...40 V AC
Input current	2.7 mA
LED display	LED (kırmızı)

Ticari bilgiler

EAN	4048879027946
eClass	27371604
Gümrük tarife no (gtip)	85414090
Menşei	CZ
Paket miktarı	1