
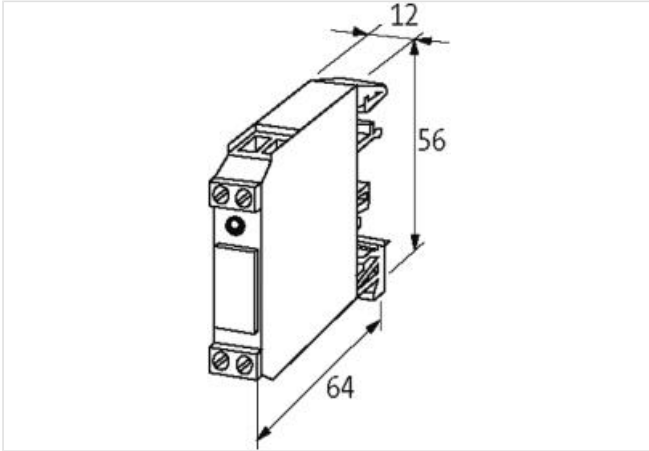


AMMS 18-1 OPTO-COUPLER MODULE

IN: 30 VDC - OUT: 30 VDC / 1,2 A

Transistor 2 A
24 V DC**Ürün Linki**

örnekleme

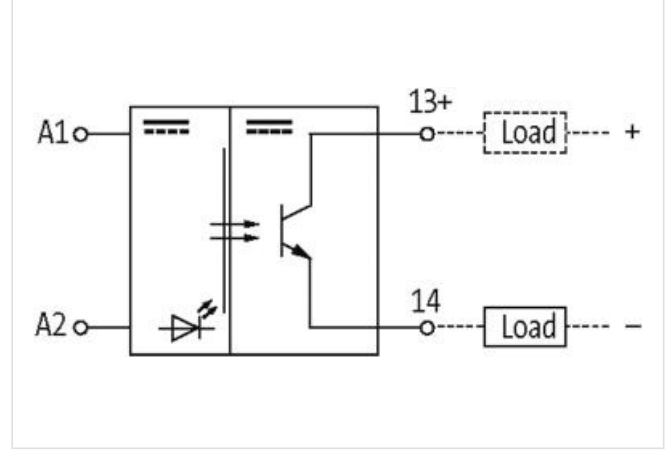

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371604
ECLASS-6.1	27371604
ECLASS-7.0	27371604
ECLASS-8.0	27371604
ECLASS-9.0	27371604
ECLASS-10.1	27371604
ECLASS-11.1	27371604
ECLASS-12.0	27371604

ETIM-5.0	EC001504
GTIN	4048879027885
Gümrük tarife no (gtip)	85414900
Paket miktarı	1
Electrical data Input	
Input voltage DC	24 V
Input voltage DC min.	6 V
Input voltage DC max.	30 V
Input current	8,5 mA
Electrical data Output	
Output voltage DC min.	6 V
Output voltage DC max.	30 V
Output current max.	1,2 A
Switch off delay max.	1 ms
Switching frequency max.	20000 Hz
Switching current min.	1 mA
Switching current max.	1,2 A
Diagnostics	
Status indication LED	red
Device protection Electrical	
Rated surge voltage	2,5 kV
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Color housing	black
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C