



RMM 11/230 V OUTPUT RELAY

IN: 230 VAC/DC - OUT: 250 VAC/DC / 6 A

1 röle; 1 NO kontağı
6 A
230 V AC
Vidalı klemensler

Ürün Linki

örnekleme

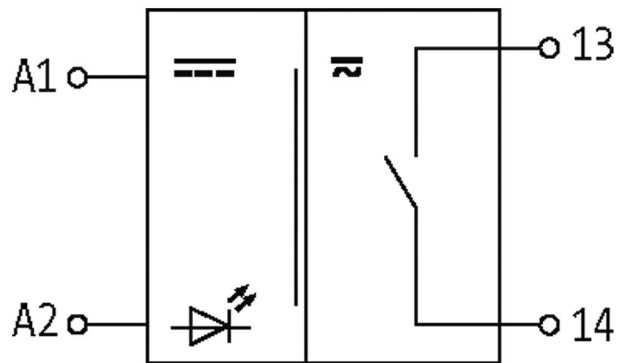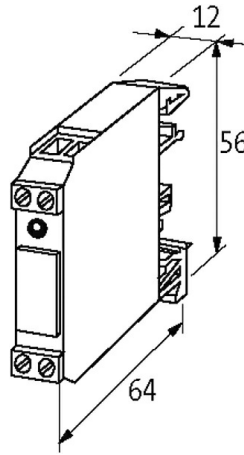

Ürün Image farklı olabilir

General data

Mech./ elect. life	20 000 000 Anahtarlama çevrimi/yüke bağlı
Test isolation voltage	4.0 kV
Mounting method	TH35 veya G32 Raya Montaj (EN 60715)
Temperature range	-20...+60 °C
Dimensions HxWxD	56x12x65 mm

Output

Switching voltage	max. 250 V AC/DC
Switching current per output	max. 6 A
Min. load current	100 mA
Power rating (voltage dependent)	max. 1250 VA/240 W
Switching frequency	max. 10 Hz
Contact material	Ag Ni 0.15 hv; Ag hv
Energize/release/contact bounce time	10/15/1.5 ms

Input

Connection voltage - current	230 V AC/DC (195...250 V AC/DC) - 3.5 mA
LED display	LED (kırmızı)

Utilization category

AC-12	6 A (24/110/230 V AC)
AC-15	4 A (24/110/230 V AC)
DC-13	2 A (24 V DC); 0.25 A (110 V DC); 0.1 A (230 V DC)

Ticari bilgiler

EAN	4048879027557
eClass	27371001
Gümrük tarife no (gtip)	85364900
Menşei	CZ
Paket miktarı	1