
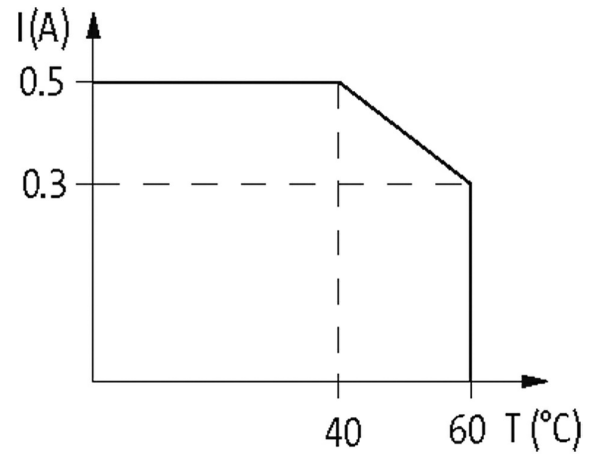



MIRO TR 90-250VAC OPTO-COUPLER MODULE

IN: 250 VAC - OUT: 48 VDC / 0,5 A

Transistör 0.5 A
230 V AC
Vidalı klemensler**Ürün Linki**

örnekleme

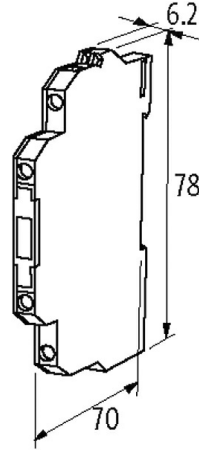

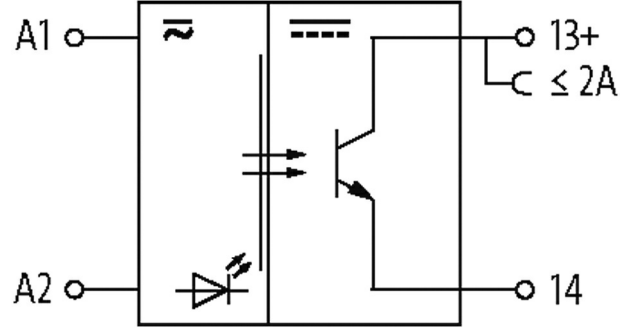

Ürün Image farklı olabilir

Onaylar



General data

Dimensions H×W×D	78×6.2×70 mm
Test isolation voltage	3.75 kV
Housing	Plastik siyah, alev geciktirici
Mounting method	Raya Montaj (EN 60715)
Temperature range	-20...+60 °C

Output

Switching voltage	5...48 V DC
Switching current per output	0.1 mA...0.5 A
Leakage current (output is open)	max. 0.3 mA
Saturation voltage (across output)	max. 1.2 V DC
Switching time ON/OFF	55/15 ms
Switching frequency	max 500/30 Hz (ohm./ind.)

Input

Voltage range ON	90...250 V AC
Voltage range OFF	0...40 V AC
Control current	7 mA
LED display	LED (sarı)

Ticari bilgiler

EAN	4048879026888
eClass	27371604
Gümrük tarife no (gtip)	85414090
Menşei	CZ
Paket miktarı	1