
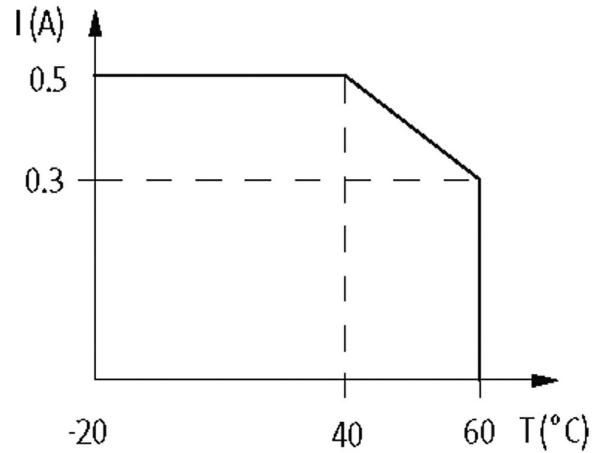
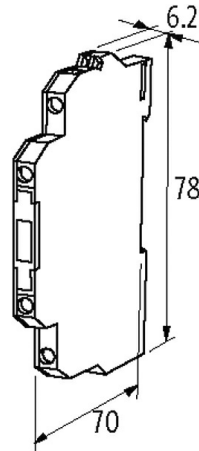


**MIRO TH 230VAC SK OPTO-COUPLER MODULE**

IN: 250 VAC - OUT: 250 VAC / 0,5A

Triac 0.5 A  
230 V AC  
Vidalı klemensler

**Ürün Linki**[örnekleme](#)

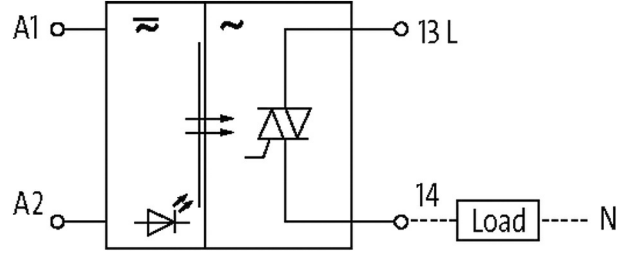

Ürün Image farklı olabilir

### Onaylar



### General data

Test isolation voltage	2.5 kV
Mounting method	Raya Montaj (EN 60715)
Housing	Plastik siyah, alev geciktirici
Temperature range	-20...+60 °C
Dimensions H×W×D	78×6.2×70 mm

### Output

Switching voltage	12...250 V AC
Switching current per output	2 mA...0.5 A
Saturation voltage (across output)	max. 1.5 V AC
Leakage current (output is open)	max. 0.3 mA
Switching time ON/OFF	10/10 ms
Switching frequency	Devreye bağlı olarak max 20 Hz

### Input

Voltage range ON	140...250 V AC
Voltage range OFF	0...80 V AC
Control current	7 mA
LED display	LED (sarı)

### Ticari bilgiler

EAN	4048879026758
eClass	27371604
Gümrük tarife no (gtip)	85414090
Menşei	CZ
Paket miktarı	1