
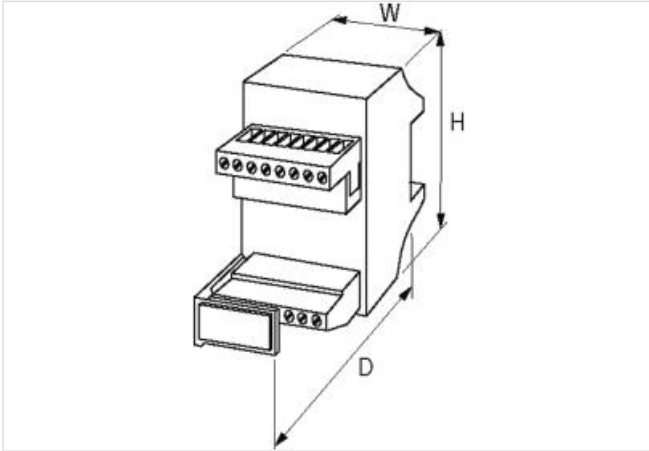


LUGS 16 FOR SIGNAL TRANSFER

250V / 8 A

16-pole
Screw plug-in terminals**Ürün Linki**

örnekleme

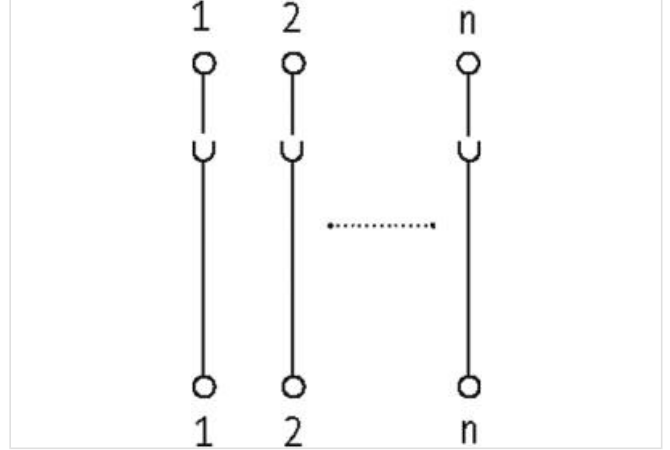

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283
GTIN	4048879026284
Gümrük tarife no (gtip)	85369010
Paket miktarı	1

Electrical data | Supply

Operating voltage AC	250 V
Operating current max.	8 A

Installation

Connection cross-section solid max.	4 mm ²
-------------------------------------	-------------------

Installation | Connection

Connection	Screw terminals SK
------------	--------------------

Device protection | Electrical

Overvoltage category (EN 60664-1)	I
-----------------------------------	---

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	45 mm
Depth	66 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C