

SOLID67 DI8 DO8 60mm M12L 5P

SOLID67 Multiprotocol Profinet or EthernetIP

Dijital Input/Outputlar

DI8 (DO8)

M12 Power, 5 kutuplu, L kodlu


60 mm

Bağlantı hatlarını online mağazada "Bağlantı sistemleri" altında bulabilirsiniz

Gövde bütünüyle dökümdür.

Ürün Linki

örnekleme

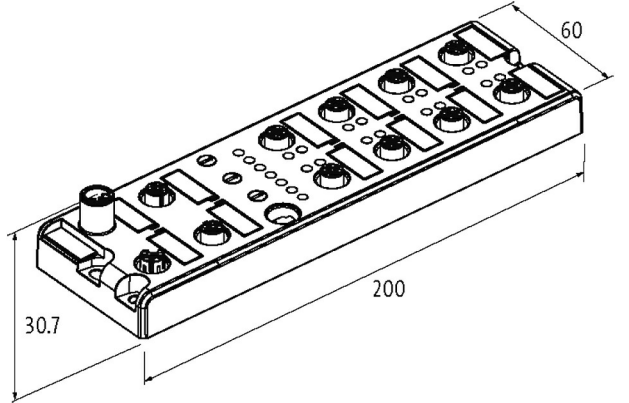

Ürün Image farklı olabilir

Onaylar



Daha Fazla Bilgi

[Bus technologies](#)
[Bus technologies](#)

General data

Mounting method	2-hole screw mounting
Temperature range	-20...+70 °C
Protection	IP67
Dimensions H×W×D	30.7×60×200 mm

Output

Actuator supply UA	24 V DC (EN 61131-2), max. 9 A
Switching current per output	max. 2 A (short-circuit and overload protected)

Input

Sensor supply US	24 V DC (EN 61131-2), max. 200 mA (M12 female), short-circuit and overload protected
Type	for 3-wire sensors or mechanical switches, PNP

Parameterization

PIN 4	Input (port X1...X4); Output (port X5...X8)
PIN 2	Input (port X1...X4); Output (port X5...X8)

Connections

Fieldbus	Ethernet 10/100 Mbit/s; M12, D-coded
Sensor-system/actuator supply	M12 Power, 5-pole, L-coded
I/O ports	M12, 5-pole, A-coded

PROFINET

Specification	V2.3, Conformance Class C (IRT)
Addressing	DCP
PROFINET Netload Class	III
MRP	yes

EtherNet/IP

QC (Quick Connect)	max. 500 ms
Addressing	DHCP, BOOTP or IP address by rotary switch
DLR (Device Level Ring)	yes
Diagnostic	
Communication status	via LED
Diagnostic via LED	per module and channel
Diagnostic via BUS	per module and channel
Actuator warning	via LED and BUS
Monitoring - under voltage	yes
Monitoring - no voltage	yes
Short-circuit and overload	yes
Cable break	per port
Ticari bilgiler	
EAN	4048879727662
eClass	27242604
Gümrük tarife no (gtip)	85389099
Menşei	DE
Paket miktarı	1.000