

MASI67 INSTALLATION TECHNOLOGY

Converter 2x profile cable to M12 female



MASI67 converter

2x profile cable to M12 (female)

Connection cables are in the online shop under "Connection Technology".

Ürün Linki

örnekleme

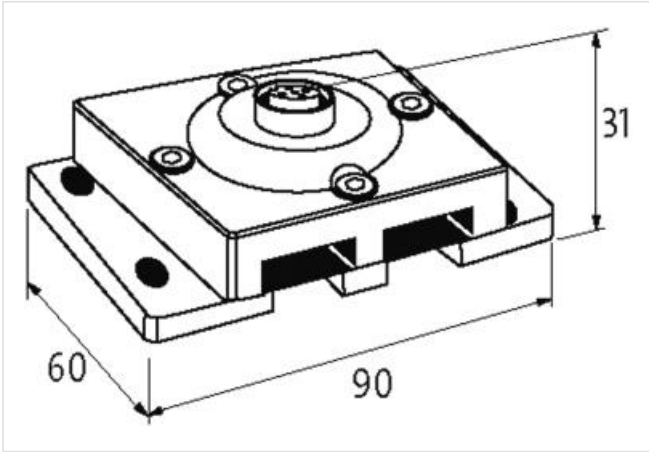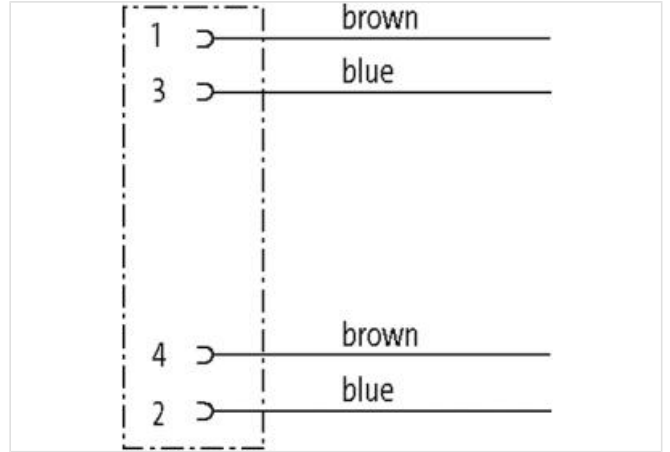

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27400209
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111

ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001583
GTIN	4048879052146
Gümrük tarife no (gtip)	85369010
Paket miktarı	1
Electrical data Supply	
Operating voltage DC max.	36 V
Total current max.	4 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Insulation strength ASI/Power	200 V
Mechanical data Mounting data	
Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	90 mm
Width	74 mm
Depth	30,5 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 60664-1
Connection type 1	
Connection type 1	Bus Out
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	AS-i +
PIN 2	0 V
PIN 3	AS-i -
PIN 4	24 V DC
PIN 5	n.c.