

Adaptor M12 Male / M12 Female

Buffer module for DI (Pin 1-3)


Adapter
Male - female
M12 – M12, 4-pole
max. 700 mA
94 µF

Ürün Linki

örnekleme




Male

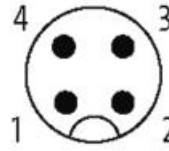


PIN 1: 24 V DC
PIN 2: Input 1X
PIN 3: GND
PIN 4: Input 0X

Female

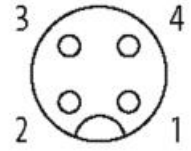

PIN 1: 24 V DC
PIN 2: Input 1X
PIN 3: GND
PIN 4: Input 0X

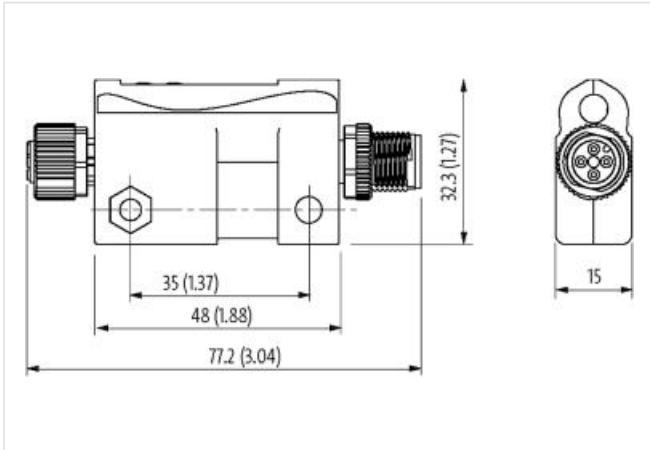

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27143423
ECLASS-6.1	27260702
ECLASS-7.0	27440102
ECLASS-8.0	27440102
ECLASS-9.0	27440102

ECLASS-10.1	27440102
ECLASS-11.1	27440102
ECLASS-12.0	27440106
ETIM-5.0	EC001855
GTIN	4048879713467
Gümrük tarife no (gtip)	85322100
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	18 V
Operating voltage DC max.	30,2 V
Total current max.	0,7 A

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	screwed, mounted

Environmental characteristics | Climatic

Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-40 °C
Storage temperature max.	85 °C
Relative humidity max. (operation)	85 %

Conformity

Product standard	EN 61131-2
------------------	------------