

MASI20 INSTALLATION TECHNOL.

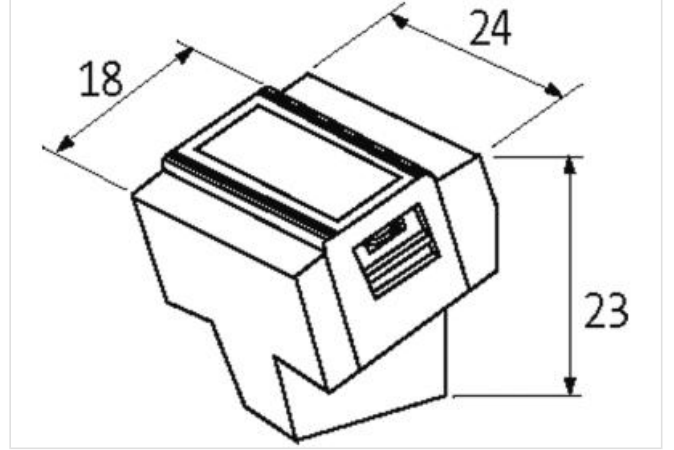
Plug terminal for AS-Interface profile cable

Plug terminal
for bus or power distributor**Ürün Linki**

örnekleme



Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27141106
ECLASS-6.1	27141104
ECLASS-7.0	27141104
ECLASS-8.0	27141104
ECLASS-9.0	27141104
ECLASS-10.1	27141104
ECLASS-11.1	27141104
ECLASS-12.0	27141104
ETIM-5.0	EC001583
GTIN	4048879050517
Gümrük tarife no (gtip)	85369010
Paket miktarı	1

Electrical data | Supply

Operating voltage DC max.	36 V
Total current max.	8 A

Mechanical data | Mounting data

Height	23 mm
Width	24 mm
Depth	18 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Connection type 1

Connection	Screw terminals SK
------------	--------------------

Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	2
PIN 1	+
PIN 2	-