

SLIM LINE POTENTIAL TERMINAL BLOCK


Potential terminal block
Slim Line

Ürün Linki

örnekleme



Ürün Image farklı olabilir

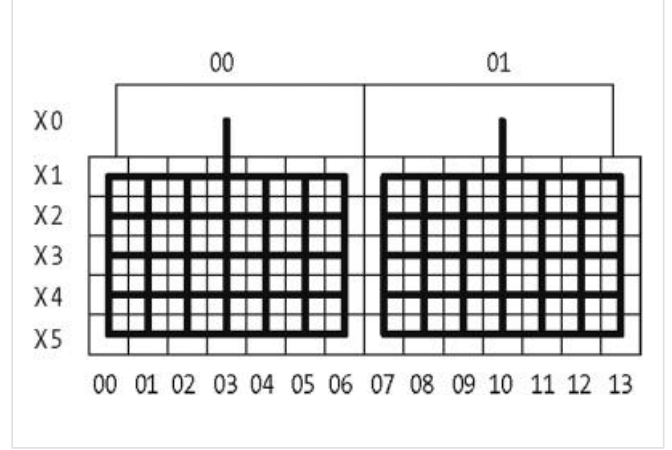

Ticari bilgiler

ECLASS-6.0	27141106
ECLASS-6.1	27141106
ECLASS-7.0	27141106
ECLASS-8.0	27141106
ECLASS-9.0	27141106
ECLASS-10.1	27141106
ECLASS-11.1	27141106
ECLASS-12.0	27141106
ETIM-5.0	EC001283
GTIN	4048879049429
Gümrük tarife no (gtip)	85369010
Paket miktarı	1

Electrical data | Supply

Operating voltage AC max.	30 V
Operating voltage DC max.	30 V
Total current max.	20 A

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20
-------------------------------------	------

Mechanical data | Mounting data

Height	70 mm
Width	56 mm
Depth	32,5 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
----------------------------	------

Operating temperature max.	55 °C
----------------------------	-------

Storage temperature min.	-40 °C
--------------------------	--------

Storage temperature max.	85 °C
--------------------------	-------

Connection type 4

Connection	Spring clamp terminals FK
------------	---------------------------

Family construction form	terminal
--------------------------	----------

Gender	female
--------	--------

Color contact carrier	green
-----------------------	-------

No. of poles	1
--------------	---

PIN 1	00
-------	----

Connection	Spring clamp terminals FK
------------	---------------------------

Family construction form	terminal
--------------------------	----------

Gender	female
--------	--------

Color contact carrier	green
-----------------------	-------

No. of poles	1
--------------	---

PIN 1	01
-------	----

Connection	Spring clamp terminals FK
------------	---------------------------

Family construction form	terminal
--------------------------	----------

Gender	female
--------	--------

Color contact carrier	black
-----------------------	-------

No. of poles	7
--------------	---

PIN 1	00
-------	----

PIN 2	01
-------	----

PIN 3	02
-------	----

PIN 4	03
-------	----

PIN 5	04
-------	----

PIN 6	05
-------	----

PIN 7	06
-------	----

Connection	Spring clamp terminals FK
------------	---------------------------

Family construction form	terminal
--------------------------	----------

Gender	female
--------	--------

Color contact carrier	black
-----------------------	-------

No. of poles	7
--------------	---

PIN 1	07
-------	----

PIN 2	08
-------	----

PIN 3	09
-------	----

PIN 4	10
-------	----

PIN 5	11
-------	----

PIN 6	12
-------	----

PIN 7	13
-------	----