

CUBE20 DIGITAL INPUT MODULE

32 digital inputs


Expansion module
DI32 - (E)

Ürün Linki

örnekleme



Ürün Image farklı olabilir

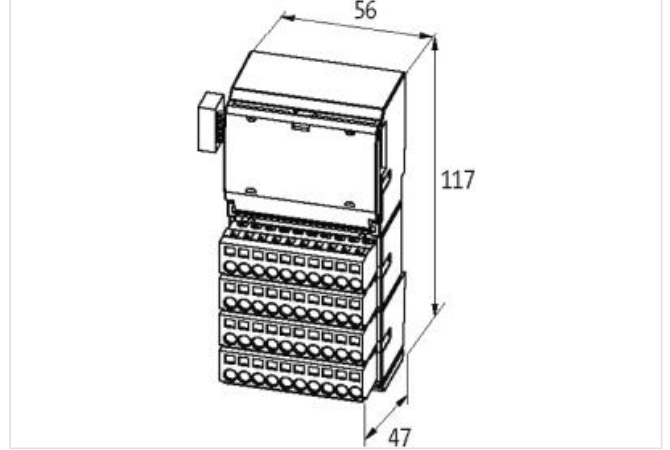

Ticari bilgiler

ECLASS-6.0	27242604
ECLASS-6.1	27242604
ECLASS-7.0	27242604
ECLASS-8.0	27242604
ECLASS-9.0	27242604
ECLASS-10.1	27242604
ECLASS-11.1	27242604
ECLASS-12.0	27242604
ETIM-5.0	EC001599
GTIN	4048879049344
Gümrük tarife no (gtip)	85176200
Paket miktarı	1

Electrical data | Supply

Norm operating voltage	EN 61131-2
Operating voltage US DC	24 V
Current consumption max.	25 mA
Total current UA max.	12 A
module supply	via system connection

Electrical data | Input

Type input	PNP (EN 61131-2)
Input filter time	1 ms
Current carrying capacity max.	0,7 A

Diagnostics

Diagnostic	Under voltage
Diagnostic via BUS	per module and channel
Diagnostic via LED	per module
Short circuit diagnosis	yes
LED display	Ethernet connection/data traffic
Overload diagnosis	yes

Installation

Connection cross section max.	2,5 mm ²
-------------------------------	---------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20
Galvanic separation (operating voltage)	yes
Galvanic separation input/input	yes

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	117 mm
Width	56 mm
Depth	47 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	55 °C
Storage temperature min.	-20 °C
Storage temperature max.	85 °C

Connection type 4

Connection type 1	X0
Connection type 2	X1
Connection type 3	X2
Connection type 4	X3
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10
PIN 1	DI 0
PIN 2	DI 1
PIN 3	DI 2
PIN 4	DI 3
PIN 5	DI 4
PIN 6	DI 5
PIN 7	DI 6
PIN 8	DI 7
PIN 9	UI
PIN 10	UI
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10
PIN 1	DI 8
PIN 2	DI 9
PIN 3	DI 10

PIN 4	DI 11
PIN 5	DI 12
PIN 6	DI 13
PIN 7	DI 14
PIN 8	DI 15
PIN 9	0 V
PIN 10	0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10
PIN 1	DI 16
PIN 2	DI 17
PIN 3	DI 18
PIN 4	DI 19
PIN 5	DI 20
PIN 6	DI 21
PIN 7	DI 22
PIN 8	DI 23
PIN 9	US
PIN 10	US
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10
PIN 1	DI 24
PIN 2	DI 25
PIN 3	DI 26
PIN 4	DI 27
PIN 5	DI 28
PIN 6	DI 29
PIN 7	DI 30
PIN 8	DI 31
PIN 9	0 V
PIN 10	0 V