

MASI67 INSTALLATION TECHNOLOGY

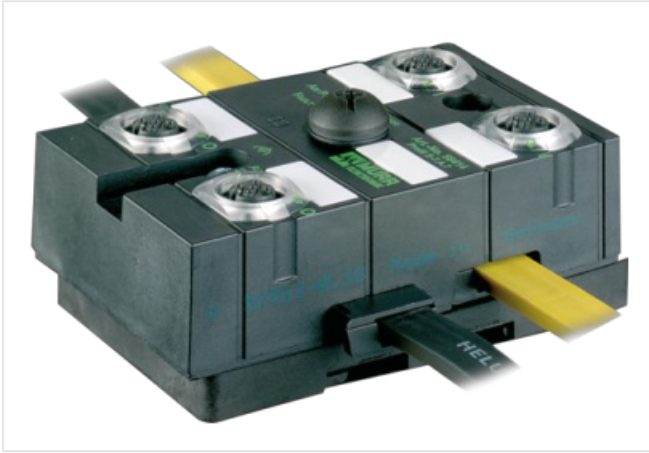
Conversion from profile cable to 4xM12, 2x power

2x Aux. Power

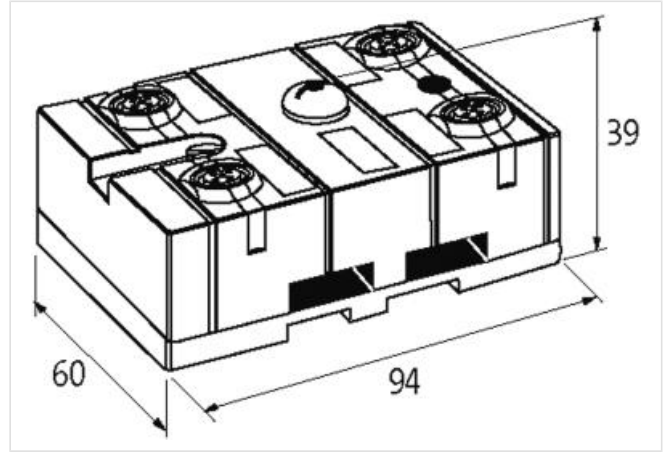
MASI67 passive distribution box

Connection cables are in the online shop under "Connection Technology".

Housing fully potted.

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27279219
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001600
GTIN	4048879048972
Gümrük tarife no (gtip)	85369010
Paket miktarı	1

Electrical data | Supply

Operating voltage external DC min.	10 V
Operating voltage external DC max.	48 V
Bus voltage AS-Interface DC min.	26,5 V
Bus voltage AS-Interface DC max.	31,6 V
Current consumption AS-i port max.	4000 mA
Total current max.	8 A

Device protection | Electrical

Degree of protection (EN IEC 60529) IP67

Mechanical data | Mounting data

Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	94 mm
Width	60 mm
Depth	39 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Connection type 2

Connection type 1	Bus Out
Connection type 2	Bus Out
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	AS-i +
PIN 2	Aux Power 1 -
PIN 3	AS-i -
PIN 4	Aux Power 1 +
PIN 5	n.c.
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	AS-i +
PIN 2	Aux Power 2 -
PIN 3	AS-i -
PIN 4	Aux Power 2 +
PIN 5	n.c.