

Gateway Ethernet-IP/AS-i, 1 Master, P24

Spec. 3.0, Diagnosis Field bus, Power 24

AS-Interface/EtherNet/IP

Power 24V

Specification 3.0

Diagnostic via BUS

Current manuals, GSD/type data can be downloaded at: www.murrelektronik.com

Other gateways on request.

Gateway-Singlemaster

AS-Interface data decoupling integrated

AS-Interface duplicate address detection



AS-Interface EMC detector integrated

Ürün Linki

örnekleme



Ürün Image farklı olabilir

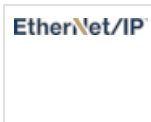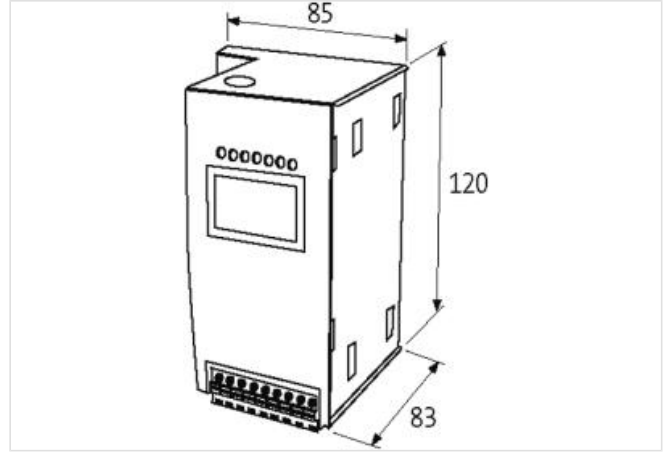

Ticari bilgiler

ECLASS-6.0	27242208
ECLASS-6.1	27242608
ECLASS-7.0	27242608
ECLASS-8.0	27242608
ECLASS-9.0	27242608
ECLASS-10.1	27242608
ECLASS-11.1	27242608
ECLASS-12.0	27242608
ETIM-5.0	EC001604
GTIN	4048879496674
Gümrük tarife no (gtip)	85176200
Paket miktarı	1

Electrical data

Rated operating current AS-Interface max.	250 mA
Security level	PELV

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	20 V
Operating voltage DC max.	30,6 V

Industrial communication

Supported protocol	EtherNet/IP
--------------------	-------------

Industrial communication | AS-Interface

AS-i specification	V3.0
Number of slaves max.	62
Diagnostic interface serial	RJ45/Fieldbus
Cycle time AS-i	150 µs × (number of slaves + 2)

Installation | Connection

Family construction form	RJ45
--------------------------	------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20
Rated insulation voltage	500 V

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	120 mm
Width	85 mm
Depth	83 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	55 °C
Storage temperature min.	-25 °C
Storage temperature max.	85 °C

Conformity

Product standard	EN 61131-2, EN 62026-2
------------------	------------------------