

IMPACT20 ETHERNET-IP, DIGITAL OUTPUT MODULE

16 digital outputs

Digital outputs

DO16 - 0.5 A

Connection cables are in the online shop under "Connection Technology".


Housing fully potted.

Ürün Linki

örnekleme



Ürün Image farklı olabilir

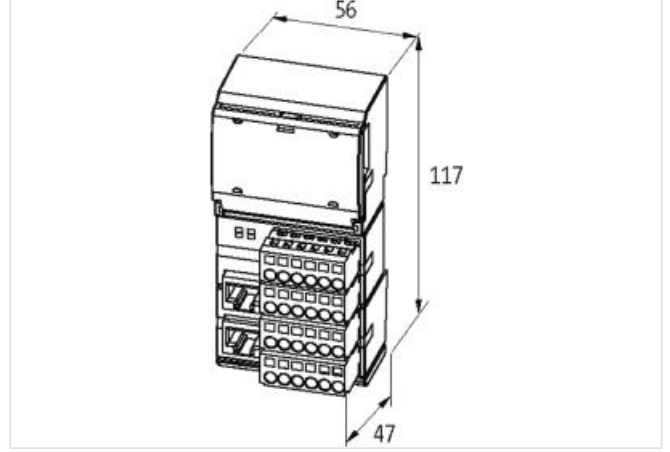

Ticari bilgiler

ECLASS-6.0	27242604
ECLASS-6.1	27242604
ECLASS-7.0	27242604
ECLASS-8.0	27242604
ECLASS-9.0	27242604
ECLASS-10.1	27242604
ECLASS-11.1	27242604
ECLASS-12.0	27242604
ETIM-5.0	EC001599
GTIN	4048879047968
Gümrük tarife no (gtip)	85389099
Paket miktarı	1

Electrical data | Supply

Total current max.	8 A
Total current UA max.	8 A

Electrical data | Output

Overload resistant	yes
Short-circuit protected	yes
Output current per pin max.	0,5 A

Industrial communication | Ethernet/IP

EtherNet/IP addressing BOOTP, DHCP, Rotary switch

Diagnostics

Diagnostic	No voltage, Under voltage
Diagnostic via BUS	per module and channel
Diagnostic via LED	per module and channel
Short circuit diagnosis	yes
LED display	Ethernet connection/data traffic
Overload diagnosis	yes

InstallationConnection cross section max. 2,5 mm²**Device protection | Electrical**

Degree of protection (EN IEC 60529) IP20

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	117 mm
Width	56 mm
Depth	47 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	55 °C
Storage temperature min.	-20 °C
Storage temperature max.	70 °C

Connection type 5

Connection type 1	X0
Connection type 2	X1
Connection type 3	X2
Connection type 4	X3
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	6
PIN 1	CH 00
PIN 2	CH 01
PIN 3	CH 02
PIN 4	CH 03
PIN 5	UI
PIN 6	0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	6
PIN 1	CH 10
PIN 2	CH 11
PIN 3	CH 12
PIN 4	CH 13
PIN 5	UA
PIN 6	0 V
Connection	Spring clamp terminals FK

Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	6
PIN 1	CH 20
PIN 2	CH 21
PIN 3	CH 22
PIN 4	CH 23
PIN 5	n.c.
PIN 6	0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	6
PIN 1	CH 30
PIN 2	CH 31
PIN 3	CH 32
PIN 4	CH 33
PIN 5	FE
PIN 6	FE
Family construction form	RJ45
Gender	female
Color contact carrier	black
No. of poles	8
PIN 1	TX +
PIN 2	TX -
PIN 3	RX +
PIN 4	n.c.
PIN 5	n.c.
PIN 6	RX -
PIN 7	n.c.
PIN 8	n.c.