

CUBE67 ACCESSORIES

System interface connector

M12

Female straight

Internal system connection
with mounting socket


Flange, hole spacing 30 mm, bore 3.3 mm

Ürün Linki

örnekleme



Ürün Image farklı olabilir

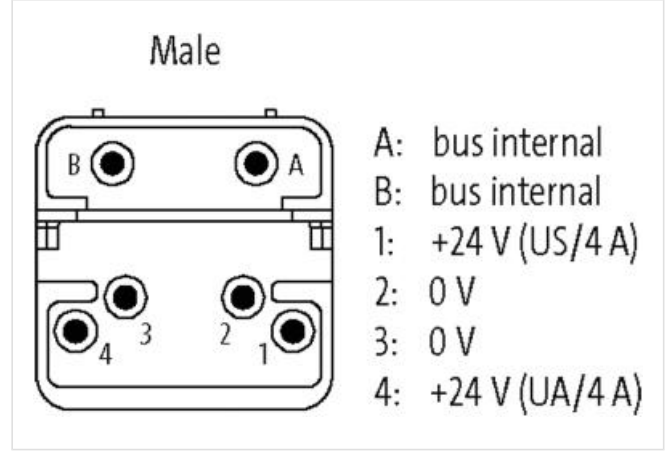

Ticari bilgiler

ECLASS-6.0	27242692
ECLASS-6.1	27242692
ECLASS-7.0	27242692
ECLASS-8.0	27242692
ECLASS-9.0	27242692
ECLASS-10.1	27242692
ECLASS-11.1	27242692
ECLASS-12.0	27242692
ETIM-5.0	EC001583
GTIN	4048879047890
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Operating current max.	4 A

Installation | Connection

Connection information	Han-Brid®, 6-polig
Family construction form	M12
Gender	female
Mating cycles min.	500

Installation | Pin assignment

No. of poles	6
--------------	---

Device protection | Electrical

Degree of protection (EN IEC 60529) IP65

Mechanical data | Mounting data

Height	80,5 mm
Width	40 mm
Depth	40 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	85 °C