

MIRO BT

IP65 Bluetooth Master/Slave PROFINET

PROFINET

Bluetooth Master/Slave

100 Mbit/s


Connection cables are in the online shop under "Connection Technology".

Ürün Linki

örnekleme



Ürün Image farklı olabilir

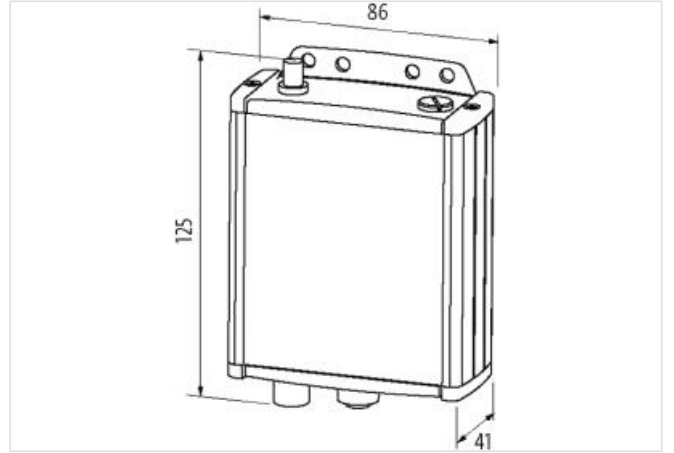

Ticari bilgiler

ECLASS-6.0	19170101
ECLASS-6.1	27242602
ECLASS-7.0	27242602
ECLASS-8.0	27242602
ECLASS-9.0	27242602
ECLASS-10.1	27242602
ECLASS-11.1	27242602
ECLASS-12.0	27242602
ETIM-5.0	EC001604
ETIM-6.0	EC001604
ETIM-7.0	EC001604
GTIN	4048879582414
Gümrük tarife no (gtip)	85176200
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Operating current max.	150 mA

Industrial communication

Radio frequency	2.4 GHz Bluetooth
Transmission power	100 mW

Installation | Connection

Antenna connection	SMA-female (50 Ω)
Mounting set	M4

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Mechanical data | Material data

Color housing	black
Material housing	Metal

Mechanical data | Mounting data

Mounting method	screwed
Height	125 mm
Width	86 mm
Depth	41 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	75 °C

Conformity

Product standard	EN 61131-2
------------------	------------

Connection type 4

Connection type 1	10M / 100M
Connection type 2	24 V DC
Connection type 3	Ant
Family construction form	M12
Gender	female
Color contact carrier	green
Coding	D
No. of poles	4
PIN 1	TD +
PIN 2	RD +
PIN 3	TD -
PIN 4	RD -
Family construction form	M12
Gender	male
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	25 V DC
PIN 3	0 V
PIN 5	PE
Family construction form	SMA
Gender	female
No. of poles	2
PIN 1	Signal
PIN 2	PE
Family construction form	USB Mini
Gender	female
No. of poles	5