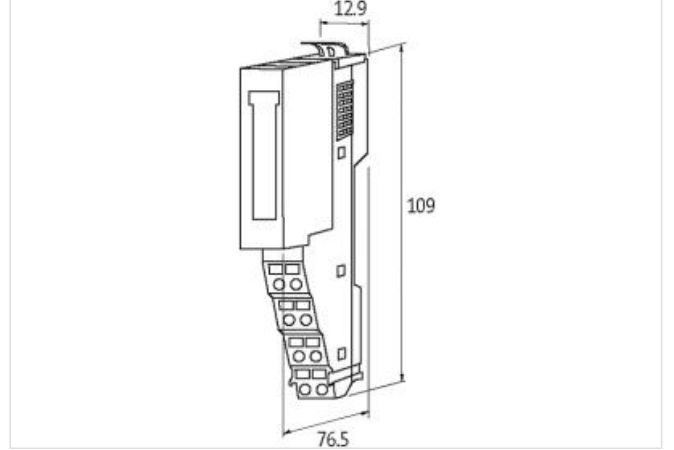


CUBE20S COMMUNICATION MODULE

RS422/485

RS422
RS485**Ürün Linki****örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27242605
ECLASS-7.0	27242605
ECLASS-8.0	27242605
ECLASS-9.0	27242605
ETIM-5.0	EC001604
GTIN	4048879422918
Gümrük tarife no (gtip)	85389099
Paket miktarı	1

Electrical data | Supply

Current consumption max.	100 mA
module supply	via system connection

Industrial communication

Transmission rate min.	150 KBit/s
Data transmission rate max.	115,2 KBit/s

Diagnostics

Diagnostic	Under voltage
Diagnostic via BUS	per module
Diagnostic via LED	per module and channel
Short circuit diagnosis	yes
LED display	Ethernet connection/data traffic
Overload diagnosis	yes

Device protection | Electrical

Degree of protection (EN IEC 60529) IP20

Mechanical data | Mounting data

Mounting method geschnappt
Suitable for mounting type mounting rail, (EN 60715)
Height 109 mm
Width 12,9 mm
Depth 76,5 mm

Environmental characteristics | Climatic

Operating temperature min. 0 °C
Operating temperature max. 60 °C
Storage temperature min. -25 °C
Storage temperature max. 70 °C

Connection type 2

Connection type 1 Power
Connection type 2 Power
Connection Spring clamp terminals FK
Family construction form terminal
Gender female
No. of poles 8
PIN 1 n.c.
PIN 2 24 V DC
PIN 3 0 V
PIN 4 24 V DC Sys
PIN 5 n.c.
PIN 6 24 V DC
PIN 7 0 V
PIN 8 0 V Sys
Connection Spring clamp terminals FK
Family construction form terminal
Gender female
No. of poles 8
PIN 1 TXD-P
PIN 2 RXD-P / TXD / RXD-P
PIN 3 RTS
PIN 4 TERM
PIN 5 TXD-N
PIN 6 RXD-N / TXD / RXD-N
PIN 7 GND_ISO
PIN 8 TERM