

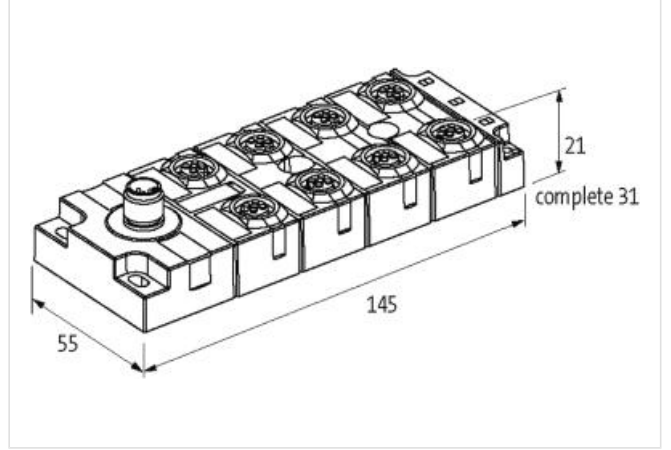
Tree 8TX IP67 Metal - Unmanaged Switch - 8xM12

8 port unmanaged switch

Connection cables are in the online shop under "Connection Technology".

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	19170106
ECLASS-6.1	19170106
ECLASS-7.0	19170106
ECLASS-8.0	19170106
ECLASS-9.0	19170402
ECLASS-10.1	19170402
ECLASS-11.1	19170402
ECLASS-12.0	19170402
ETIM-5.0	EC000734
GTIN	4048879536509
Gümrük tarife no (gtip)	85176200
Paket miktarı	1

Electrical data | Supply

Operating voltage DC min.	9 V
Operating voltage DC max.	30 V

Industrial communication

Data transmission rate max.	100 MBit/s
-----------------------------	------------

Industrial communication | Ethernet functionality

Auto-crossover	yes
Auto-negotiation	yes
duplex	Full duplex
Switch type	unmanaged
VLAN unmanaged (IEEE 802.1Q)	yes

Diagnostics

Alarm contact	no
Diagnostic	No voltage
LED display	Ethernet connection/data traffic

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
-------------------------------------	------

Mechanical data | Material data

Coating housing	Nickel
Material housing	Zinc die-casting

Mechanical data | Mounting data

Suitable for mounting type	4 hole screw mounting
Height	145 mm
Width	55 mm
Depth	31 mm

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Connection type 2

Connection type 1	4-7
Connection type 2	Power
Mounting method	inserted, screwed
Tightening torque	0,6 Nm
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	D
No. of poles	4
PIN 1	TD +
PIN 2	RD +
PIN 3	TD -
PIN 4	RD -
Family construction form	M12
Gender	male
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	24 V DC (UB 1)
PIN 2	24 V DC (UB 2)
PIN 3	0 V
PIN 4	0 V
PIN 5	PE