

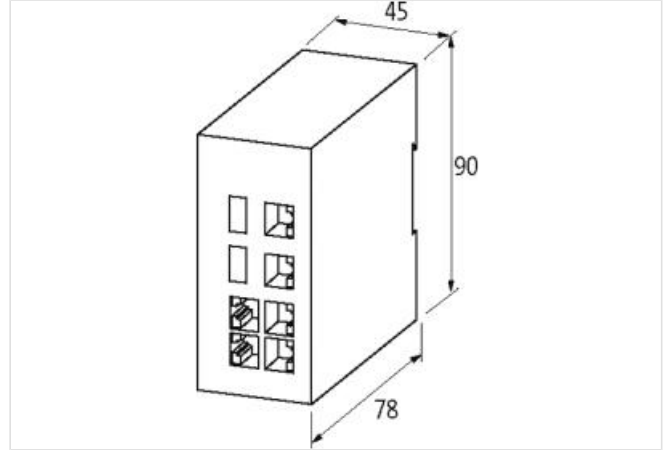
TREE 6TX ECO - UNMANAGED SWITCH - 6 PORTS

6 port unmanaged switch

Connection cables are in the online shop under "Connection Technology".

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	19170106
ECLASS-7.0	19170106
ECLASS-8.0	19170106
ECLASS-9.0	19170106
ETIM-5.0	EC000734
GTIN	4048879329569
Gümrük tarife no (gtip)	85176200
Paket miktarı	1

Electrical data | Supply

Operating voltage DC min.	9 V
Operating voltage DC max.	30 V

Industrial communication

Data transmission rate max.	100 MBit/s
-----------------------------	------------

Industrial communication | Ethernet functionality

Auto-crossover	yes
Auto-negotiation	yes
duplex	Full duplex
Switch type	unmanaged
VLAN unmanaged (IEEE 802.1Q)	yes

Diagnostics

Alarm contact	no
Diagnostic	No voltage

LED display

Ethernet connection/data traffic

Installation | Connection

Number ports 6

Device protection | Electrical

Degree of protection (EN IEC 60529) IP20

Mechanical data | Material data

Color housing black

Material housing Plastic

Mechanical data | Mounting data

Mounting method geschnappt

Suitable for mounting type Mounting rail TH35, (EN 60715)

Height 90 mm

Width 45,2 mm

Depth 78 mm

Environmental characteristics | Climatic

Operating temperature min. 0 °C

Operating temperature max. 60 °C

Storage temperature min. -10 °C

Storage temperature max. 70 °C