


## Xelity 8TX Unmanaged Switch 8 Port 100Mbit

8 port unmanaged switch

Connection cables are in the online shop under "Connection Technology".

### Ürün Linki

#### örnekleme

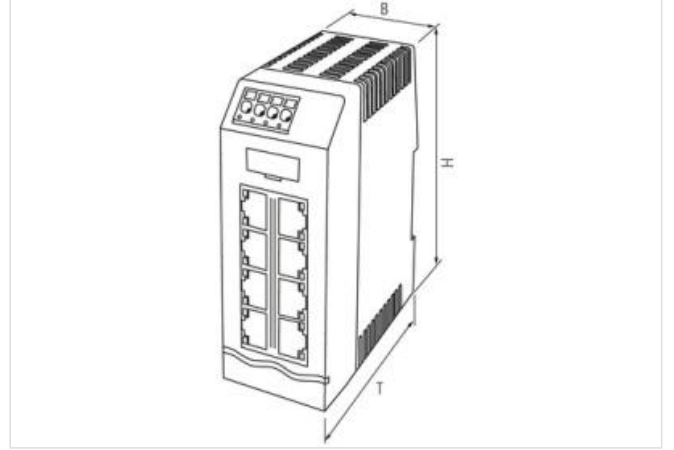

Ürün Image farklı olabilir



#### Ticari bilgiler

|                         |               |
|-------------------------|---------------|
| ECLASS-6.0              | 19170106      |
| ECLASS-6.1              | 19170106      |
| ECLASS-7.0              | 19170106      |
| ECLASS-8.0              | 19170106      |
| ECLASS-9.0              | 19170106      |
| ECLASS-10.1             | 19170402      |
| ECLASS-11.1             | 19170402      |
| ECLASS-12.0             | 19170402      |
| ETIM-5.0                | EC000734      |
| GTIN                    | 4048879798808 |
| Gümrük tarife no (gtip) | 85176200      |
| Paket miktarı           | 1             |

#### Electrical data | Supply

|                           |        |
|---------------------------|--------|
| Operating voltage DC min. | 9,5 V  |
| Operating voltage DC max. | 31,5 V |
| Power consumption max.    | 1,2 W  |
| Current consumption max.  | 50 mA  |

#### Industrial communication

|                             |            |
|-----------------------------|------------|
| Data transmission rate max. | 100 MBit/s |
|-----------------------------|------------|

#### Industrial communication | Ethernet functionality

|                  |             |
|------------------|-------------|
| Auto-crossover   | yes         |
| Auto-negotiation | yes         |
| duplex           | Full duplex |

|                                                 |                                  |
|-------------------------------------------------|----------------------------------|
| Switch type                                     | unmanaged                        |
| VLAN unmanaged (IEEE 802.1Q)                    | yes                              |
| <b>Diagnostics</b>                              |                                  |
| Alarm contact                                   | no                               |
| Diagnostic                                      | No voltage                       |
| LED display                                     | Ethernet connection/data traffic |
| <b>Device protection   Electrical</b>           |                                  |
| Degree of protection (EN IEC 60529)             | IP20                             |
| Invers-polarity protection                      | yes                              |
| Over voltage protection                         | yes                              |
| <b>Mechanical data   Material data</b>          |                                  |
| Color housing                                   | black                            |
| Material housing                                | Plastic                          |
| <b>Mechanical data   Mounting data</b>          |                                  |
| Mounting method                                 | geschnappt                       |
| Suitable for mounting type                      | Mounting rail TH35, (EN 60715)   |
| Height                                          | 105 mm                           |
| Width                                           | 41,6 mm                          |
| Depth                                           | 85,1 mm                          |
| <b>Environmental characteristics   Climatic</b> |                                  |
| Operating temperature min.                      | -25 °C                           |
| Operating temperature max.                      | 60 °C                            |
| Storage temperature min.                        | -40 °C                           |
| Storage temperature max.                        | 85 °C                            |
| <b>Connection type 2</b>                        |                                  |
| Connection type 1                               | 8                                |
| Family construction form                        | RJ45                             |
| Gender                                          | female                           |
| Color contact carrier                           | black                            |
| No. of poles                                    | 8                                |
| PIN 1                                           | TD +                             |
| PIN 2                                           | TD -                             |
| PIN 3                                           | RD +                             |
| PIN 4                                           | n.c.                             |
| PIN 5                                           | n.c.                             |
| PIN 6                                           | RD -                             |
| PIN 7                                           | n.c.                             |
| PIN 8                                           | n.c.                             |
| Connection                                      | Spring clamp terminals FK        |
| Family construction form                        | terminal                         |
| Gender                                          | female                           |
| Color contact carrier                           | green                            |
| No. of poles                                    | 4                                |
| PIN 1                                           | 24 V DC (UB 1)                   |
| PIN 2                                           | 0 V                              |
| PIN 3                                           | PE                               |
| PIN 4                                           | n.c.                             |