

Xenterra 16TX unmanaged Switch wallmounted 16 Port 100Mbit


16 port unmanaged switch
Key-hole mounting/screwable
Connection cables are in the online shop under "Connection Technology".

Ürün Linki

örnekleme



Ürün Image farklı olabilir

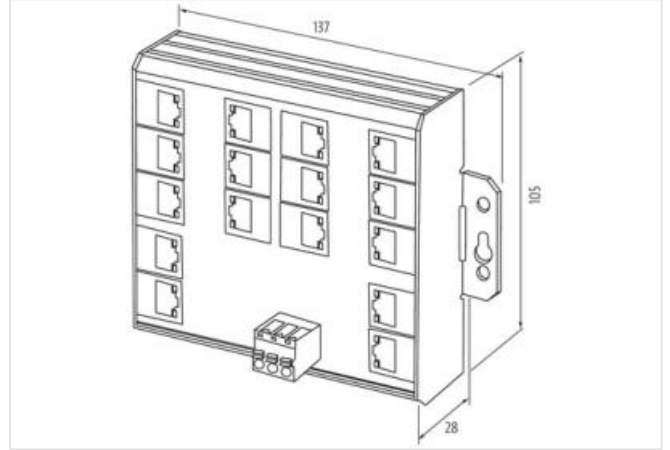

Ticari bilgiler

ECLASS-6.1	19170106
ECLASS-7.0	19170106
ECLASS-8.0	19170106
ECLASS-9.0	19170402
ECLASS-10.1	19170402
ECLASS-11.1	19170402
ECLASS-12.0	19170402
GTIN	4048879830430
Gümrük tarife no (gtip)	85176200
Paket miktarı	1

Electrical data | Supply

Operating voltage AC min.	8 V
Operating voltage AC max.	28 V
Operating voltage DC min.	9 V
Operating voltage DC max.	36 V

Industrial communication

Data transmission rate max.	100 MBit/s
-----------------------------	------------

Industrial communication | Ethernet functionality

Auto-crossover	yes
Auto-negotiation	yes
duplex	Full duplex
Switch type	unmanaged

VLAN unmanaged (IEEE 802.1Q) yes

Diagnostics

Alarm contact no

Diagnostic No voltage

LED display Ethernet connection/data traffic

Device protection | Electrical

Degree of protection (EN IEC 60529) IP20

Mechanical data | Material data

Color housing black

Material housing Metal

Mechanical data | Mounting data

Mounting method screwed

Suitable for mounting type Schlüssellochabhängung

Height 105 mm

Width 137 mm

Depth 28 mm

Environmental characteristics | Climatic

Operating temperature min. -40 °C

Operating temperature max. 70 °C

Storage temperature min. -40 °C

Storage temperature max. 85 °C

Connection type 1

Connection type 1 16

Family construction form RJ45

Gender female

Color contact carrier black

No. of poles 8

PIN 1 TD +

PIN 2 TD -

PIN 3 RD +

PIN 4 n.c.

PIN 5 n.c.

PIN 6 RD -

PIN 7 n.c.

PIN 8 n.c.