



IR RELAY SOCKET MODULES

Product discontinued, no alternative

for industrial relays
4 NO/NC contacts
0...230 V AC/DC
without components

Ürün Linki

örnekleme

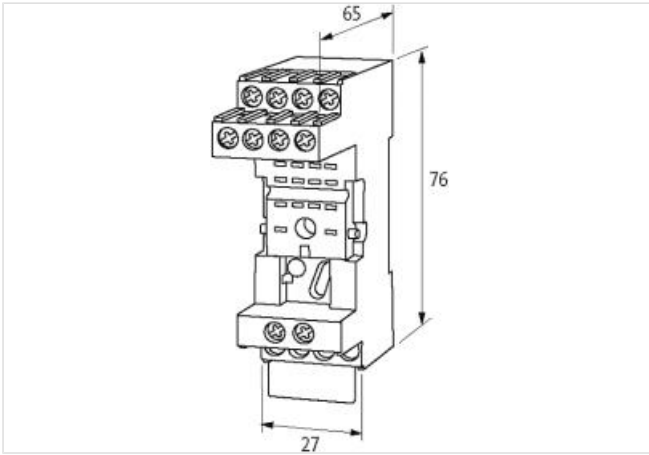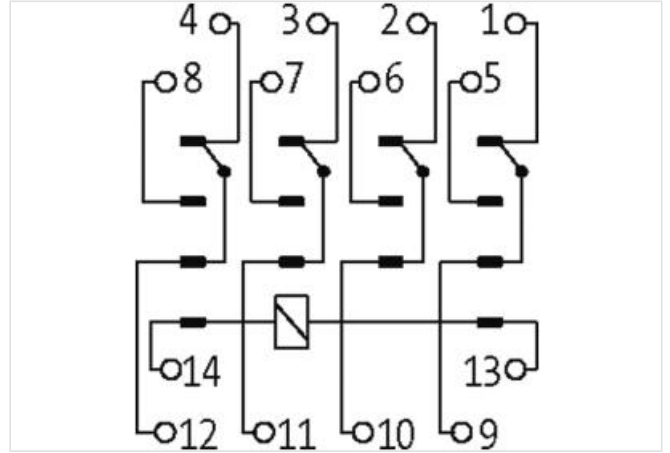

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27371603
ECLASS-7.0	27371603
ECLASS-8.0	27371603
ECLASS-9.0	27371603
ETIM-5.0	EC001437
GTIN	4048879025935

Gümrük tarife no (gtip)	85366990
-------------------------	----------

Paket miktarı	1
---------------	---

Electrical data | Output

Switching voltage AC max.	250 V
---------------------------	-------

Switching voltage DC max.	110 V
---------------------------	-------

Switching current max.	5 A
------------------------	-----

Installation | Connection

Connection	Spring clamp terminals FK
------------	---------------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP40
-------------------------------------	------

Mechanical data | Mounting data

Mounting method	geschnappt
-----------------	------------

Suitable for mounting type	mounting rail, (EN 60715)
----------------------------	---------------------------

Height	76,5 mm
--------	---------

Width	27 mm
-------	-------

Depth	65 mm
-------	-------