



ASSEMBLY MODULE MP 6 S

Mounting rail / screw-type terminal

6 pairs of solder pins
screw terminals connected to solder pin pairs

Ürün Linki

örnekleme

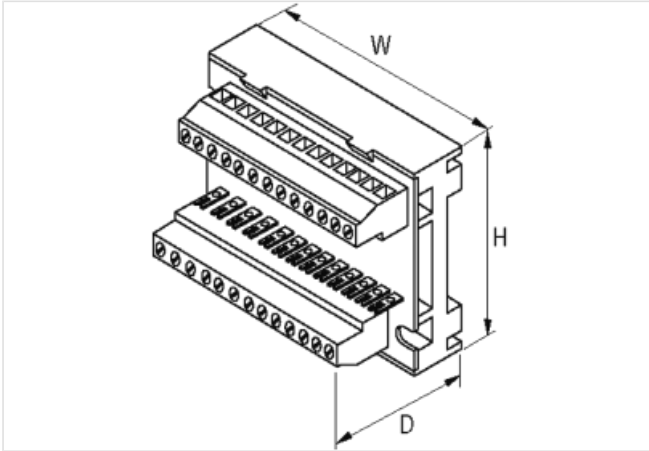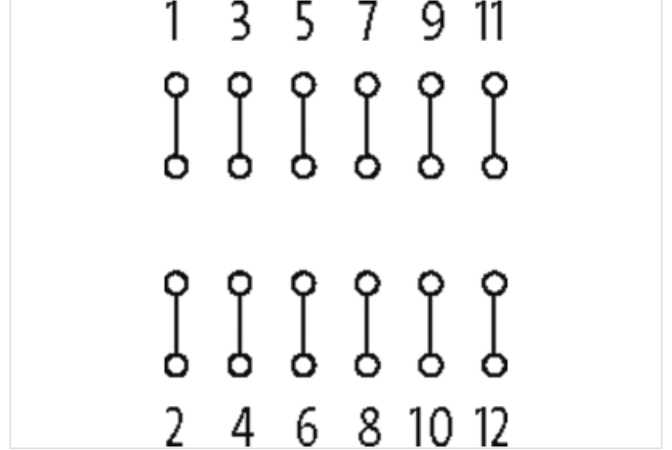

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27260710
ECLASS-6.1	27141149
ECLASS-7.0	27141149
ECLASS-8.0	27141149
ECLASS-9.0	27141149
ECLASS-10.1	27141149
ECLASS-11.1	27141149
ECLASS-12.0	27141149
ETIM-5.0	EC002780
GTIN	4048879042239
Gümrük tarife no (gtip)	85369010
Paket miktarı	1

Electrical data | Supply

Operating voltage AC max.	250 V
Operating voltage DC max.	250 V
Operating current max.	5 A

Installation

Connection cross section max.	4 mm ²
-------------------------------	-------------------

Installation | Connection

Connection	Screw terminals SK
Connection information	Lötstützpunktpaare (Raster 5 mm)

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Housing properties	open design
Material housing	Plastic

Mechanical data | Mounting data

Distance of solder pins	50 mm
Mounting method	screwed, geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	63 mm
Width	90 mm
Depth	36 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C