

MKS - D 10/1300 - 1 DIODE MODULES

Mounting rail / screw-type terminal

Universal diode 1 300 V, 1 A



10 diodes

separation contact via pluggable jumpers

Diode modules are suitable for the suppression of inductive loads (valve, contactor, etc.)

Ürün Linki

örnekleme

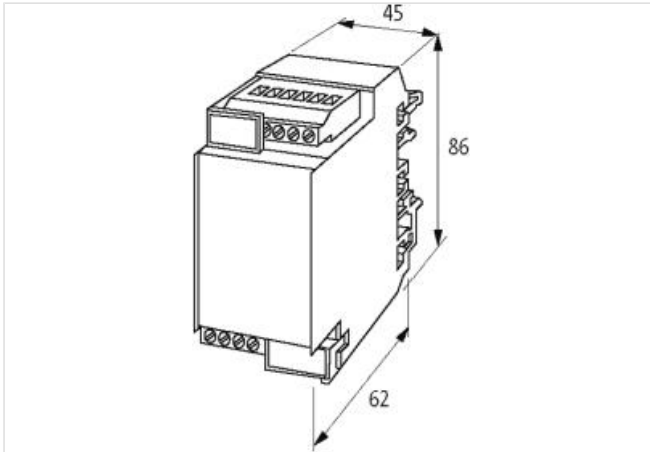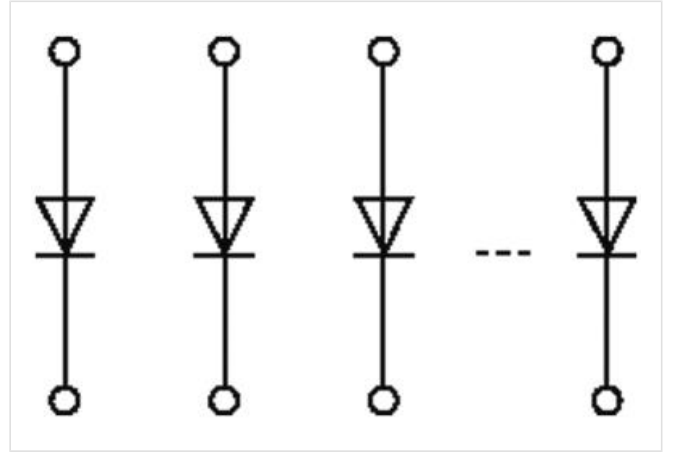

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-8.0	27371010
ECLASS-9.0	27371010
ECLASS-10.1	27371010

ECLASS-11.1	27371010
ECLASS-12.0	27371010
ETIM-5.0	EC002780
GTIN	4048879041874
Gümrük tarife no (gtip)	85411000
Paket miktarı	1
Electrical data Supply	
Operating voltage AC max.	48 V
Operating voltage DC max.	48 V
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	86 mm
Width	45 mm
Depth	62 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Connection type 1	
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	20