

MKS/BCD-1300 DIODE MODULES



Mounting rail / screw-type terminal

Universal diode 1 300 V, 1 A

Diode logic for converting hexadecimal to binary numbers

Ürün Linki

örnekleme

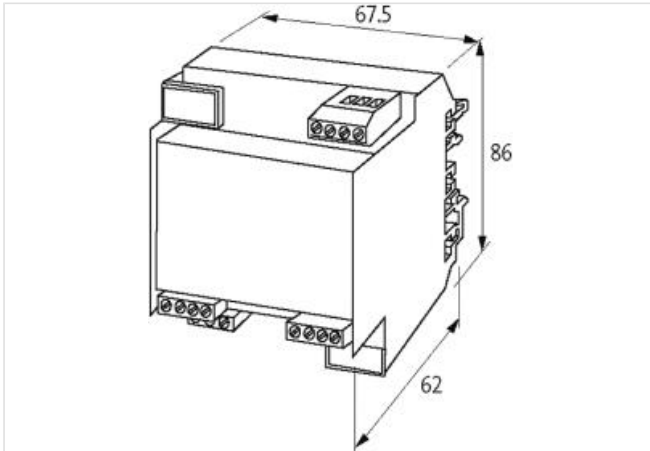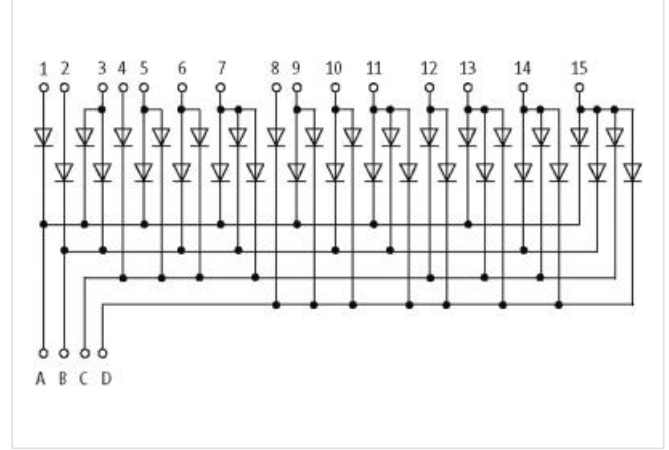

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-8.0	27371010
ECLASS-9.0	27371010
ECLASS-10.1	27371010
ECLASS-11.1	27371010
ECLASS-12.0	27371010

ETIM-5.0	EC002780
GTIN	4048879041829
Gümrük tarife no (gtip)	85411000
Paket miktarı	1

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	86 mm
Width	67,5 mm
Depth	62 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 2

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	4
PIN 1	D
PIN 2	C
PIN 3	B
PIN 4	A
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	15