



MKS-10/LDP 1300-1 M DIODE MODULES

Mounting rail / screw-type terminal

Universal diode 1 300 V, 1 A
10 pair of diodes
Common potential anode

Ürün Linki

örnekleme

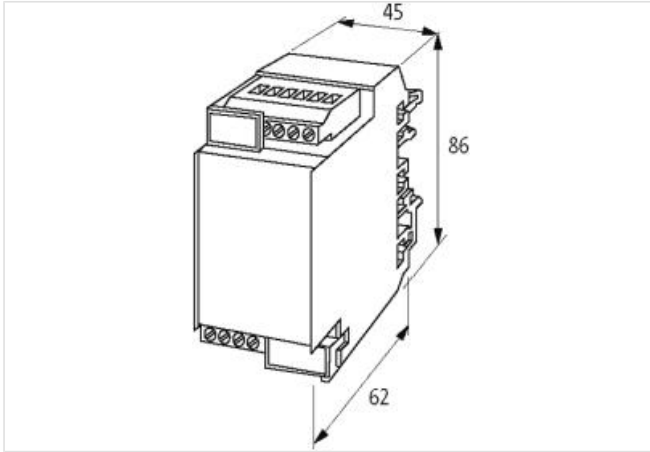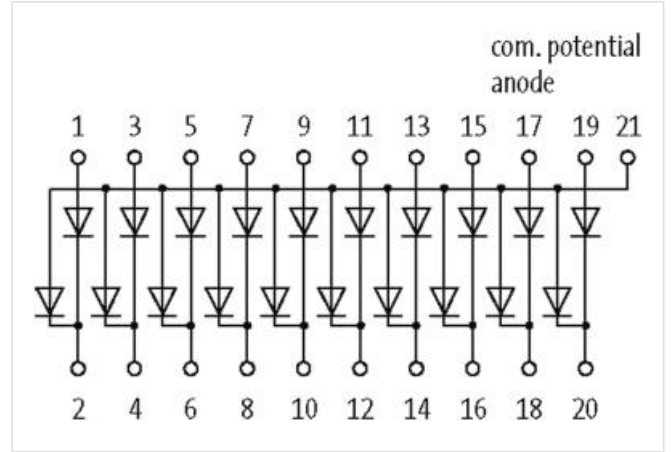

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-8.0	27371010
ECLASS-9.0	27371010
ECLASS-10.1	27371010

ECLASS-11.1	27371010
ECLASS-12.0	27371010
ETIM-5.0	EC002780
GTIN	4048879041768
Gümrük tarife no (gtip)	85411000
Paket miktarı	1

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	86 mm
Width	45 mm
Depth	62 mm

Connection type 1

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	21