

MPOT POTENTIOMETER MODULE

10K-Ohm/270 degree

270° potentiometer



10 kΩ

The 10-turn potentiometer has a decimal scale and locking lever

The potentiometer modules are fitted with standard values. They are available as 270° potentiometer and as 10-turn potentiometer with fine adjustment. They can be operated with 10 V DC or 24 V DC. A resistor reduces the voltage so that a 24 V DC voltage can be reduced to operate between approx. 0...11 V. The connection is via terminals.

Ürün Linki

örnekleme

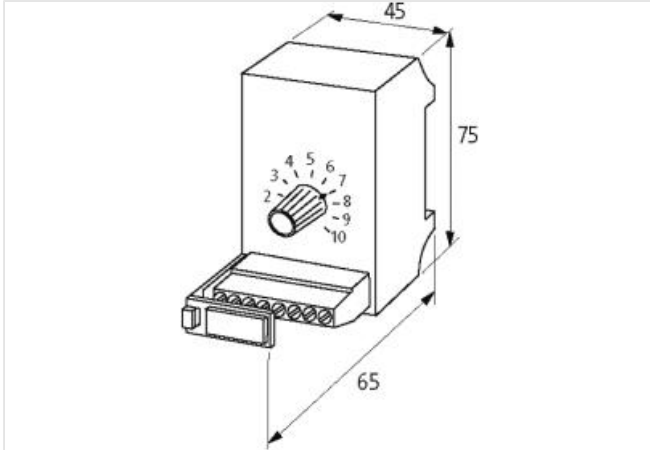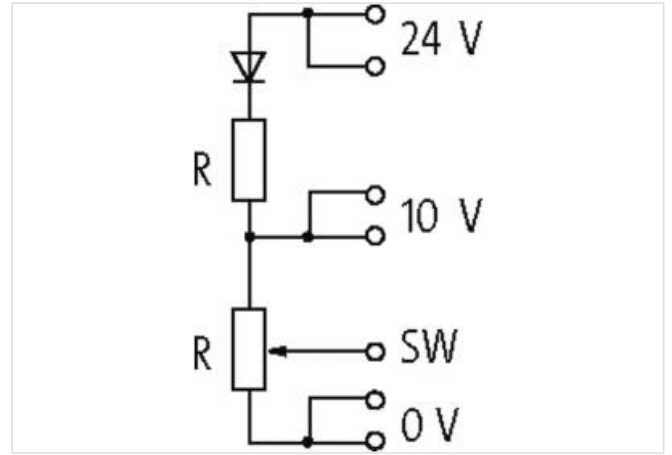

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27371227
ECLASS-6.1	27371227
ECLASS-7.0	27371227
ECLASS-8.0	27371227
ECLASS-9.0	27371227
ECLASS-10.1	27371227
ECLASS-11.1	27371227
ECLASS-12.0	27371227
ETIM-5.0	EC001027

GTIN	4048879041683
------	---------------

Gümrük tarife no (gtip)	85334010
-------------------------	----------

Paket miktarı	1
---------------	---

Electrical data

Power max.	1 W
------------	-----

Linearity	±3 %
-----------	------

Resistance	10 kΩ
------------	-------

Resistance tolerance	20 %
----------------------	------

Electrical data | Input

Power loss max.	0,25 W
-----------------	--------

Mechanical data | Mounting data

Mounting method	geschnappt
-----------------	------------

Suitable for mounting type	mounting rail, (EN 60715)
----------------------------	---------------------------

Height	75 mm
--------	-------

Width	45 mm
-------	-------

Depth	65 mm
-------	-------

Environmental characteristics | Climatic

Operating temperature min.	0 °C
----------------------------	------

Operating temperature max.	60 °C
----------------------------	-------