

HYBRID FIELD-BUS COUPLERS

Conversion electrical-electrical (passive)

CU, CU (female/male)


Han-Brid ® a registered trademark of HARTING KGaA.

Ürün Linki

örnekleme



Ürün Image farklı olabilir

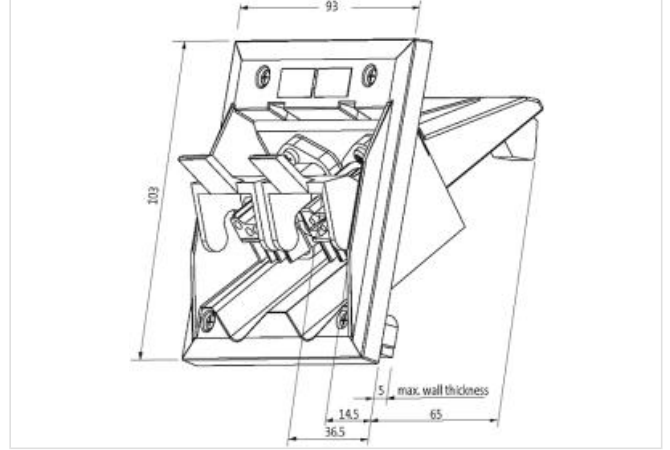

Ticari bilgiler

ECLASS-6.0	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27189217
ETIM-5.0	EC002641
GTIN	4048879041485
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
----------------------	------

Industrial communication

Data transmission rate max.	12 MBit/s
-----------------------------	-----------

Installation

Connection cross-section solid max.	0,25 mm²
Connection cross-section stranded/fine-stranded max.	2,5 mm²

Installation | Connection

Connection	Spring clamp plug-in terminals
------------	--------------------------------

Device protection

Shielded	no
----------	----

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Color housing	black
Material housing	Plastic

Mechanical data | Mounting data

Height cutout	90 mm
Width cutout	80 mm
Height	103 mm
Width	93 mm
Depth	65 mm

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	50 °C