

MSVD POWER SOCKET NEMA (GFCI)

Mounting rail

USA (2× NEMA-GFCI 5-20)

(Ground Fault Circuit Interrupter)

Screw terminals

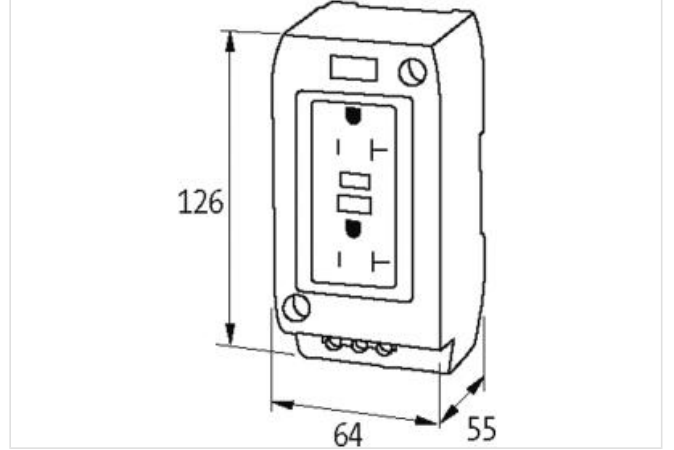
Each socket can be loaded with 20 A, however, the total load of both sockets must be below 30 A.

Ürün Linki

örnekleme



Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27189217
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC000020
GTIN	4048879041386
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Electrical data

Fault current min.	4 mA
Fault current max.	6 mA

Electrical data | Supply

Operating voltage AC	125 V
Operating current max.	20 A

Installation

Connection cross section max.	6 mm ²
-------------------------------	-------------------

Installation | Connection

Connection Screw terminals SK

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	126 mm
Width	64 mm
Depth	55 mm