

S-Lamp 22 L M12(4)

Lamp

S-Lamp 22 L M12(4)

Lamp

Mounting hole 22,3 mm

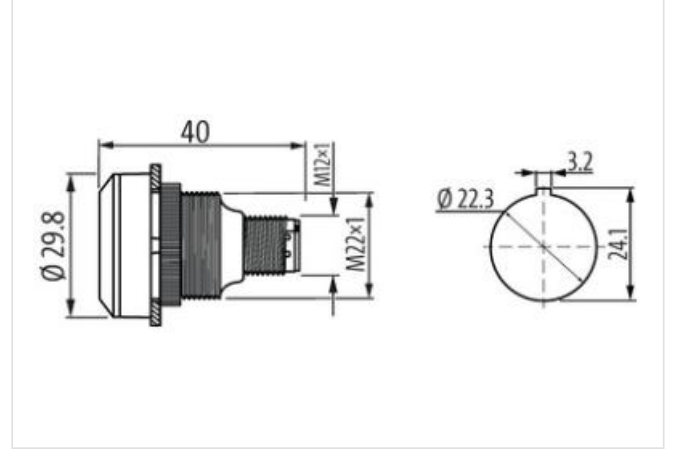
Connection M12 (4-pin)

Ürün Linki

örnekleme



Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.1	27371223
ECLASS-7.0	27371223
ECLASS-8.0	27371223
ECLASS-9.0	27371223
ECLASS-10.1	27371223
ECLASS-11.1	27371223
ECLASS-12.0	27371223
ETIM-5.0	EC000272
GTIN	4065909019245
Gümrük tarife no (gtip)	94054231
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	20 V
Operating voltage DC max.	28 V
Rated operating current	0,01 A
Operating current max.	12 mA

Electrical data | Input

Short-circuit current	1000 A
-----------------------	--------

Installation | Connection

Family construction form M12

Installation | Pin assignment

Coding	A
No. of poles	4

Device protection | Electrical

Installation height max. ASL	2000 m
Degree of protection front (EN IEC 60529)	IP66, IP67, IP69
Degree of protection back (EN IEC 60529)	IP66, IP67
Pollution Degree	2
Short circuit protective device (SCPD)	fuse 250 V / 0.1 A / 1.5 kA gG quick
Rated insulation voltage	250 V
Overvoltage category (EN 60950-1)	II

Device protection | Mechanical

UL enclosure type rating front side	type 4X
-------------------------------------	---------

Device protection | Media

Salt-spray resistance (IEC 60068-2-11)	yes
--	-----

Mechanical data

Can be illuminated	yes
Color	black
Color collar	black
Color illuminant	white
Shape collar	round
Type of illuminant	LED

Mechanical data | Material data

Material housing	Plastic
------------------	---------

Mechanical data | Mounting data

Mounting method	Threaded ring
Installation height	9,8 mm
Mounting depth	36,4 mm
Mounting hole	22,3 mm
Height	29,8 mm
Width	40 mm
Grid min.	30 mm

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	70 °C
Derating from	40 °C
Storage temperature min.	-40 °C
Storage temperature max.	90 °C
Relative humidity max. (operation)	93 %

Connection type 2

Family construction form	M12
Gender	male
Color contact carrier	black
Coding	A
No. of poles	4
PIN 2	LED (A)
PIN 3	LED (K)
Family construction form	M12
Gender	male

Coding	A
No. of poles	4
PIN 2	LED (A)
PIN 3	LED (K)