

LED-INDICATOR OPAC / RED

LED-24V IP65

(red)

24 V AC/DC

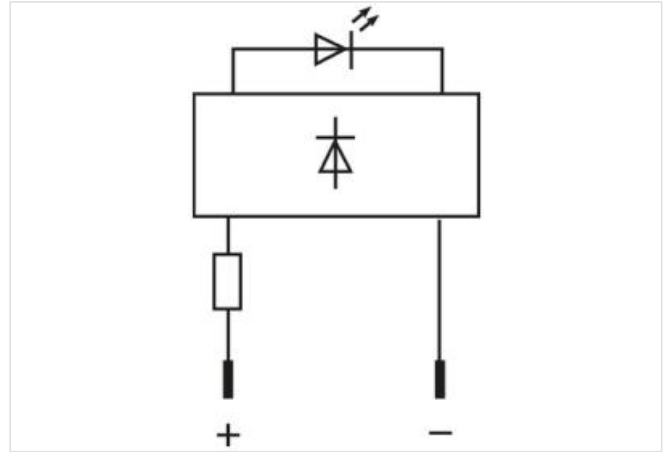
The modules are suitable for wall thickness of 1.5...5.0 mm.

Ürün Linki

örnekleme



Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
GTIN	4048879041331
Gümrük tarife no (gtip)	85318070
Paket miktarı	10

Electrical data | Supply

Operating voltage AC	24 V
Operating voltage AC min.	20,4 V
Operating voltage AC max.	26,4 V
Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption min.	8 mA
Current consumption max.	12 mA

Installation | Connection

Connection information	Faston 2.8x0.8 mm
------------------------	-------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Device protection | Media

Flame resistance flame retardant

Mechanical data

Diameter LED 5 mm

Mechanical data | Material data

Material housing Plastic

Mechanical data | Mounting data

Diameter front panel drilling 9 mm

Environmental characteristics | Climatic

Operating temperature min. -20 °C

Operating temperature max. 50 °C