

**LED-INDICATOR OPAC / RED**

LED-110V IP65

(red)

110 V AC/DC

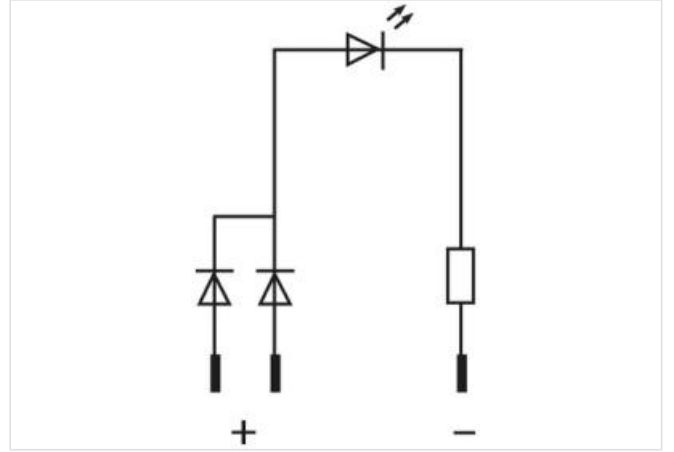
The modules are suitable for wall thickness of 1.5...5.0 mm.

**Ürün Linki**

örnekleme



Ürün Image farklı olabilir

**Ticari bilgiler**

|                         |               |
|-------------------------|---------------|
| ECLASS-6.0              | 27261590      |
| ECLASS-6.1              | 27261501      |
| ECLASS-7.0              | 27261501      |
| ECLASS-8.0              | 27261501      |
| ECLASS-9.0              | 27261501      |
| ECLASS-10.1             | 27261501      |
| ECLASS-11.1             | 27261501      |
| ECLASS-12.0             | 27261501      |
| ETIM-5.0                | EC000272      |
| GTIN                    | 4048879041324 |
| Gümrük tarife no (gtip) | 85318070      |
| Paket miktarı           | 10            |

**Electrical data | Supply**

|                           |       |
|---------------------------|-------|
| Operating voltage AC      | 110 V |
| Operating voltage AC min. | 95 V  |
| Operating voltage AC max. | 121 V |
| Operating voltage DC      | 110 V |
| Operating voltage DC min. | 95 V  |
| Operating voltage DC max. | 121 V |
| Current consumption min.  | 8 mA  |
| Current consumption max.  | 12 mA |

**Installation | Connection**

|                        |                   |
|------------------------|-------------------|
| Connection information | Faston 2.8x0.8 mm |
|------------------------|-------------------|

**Device protection | Electrical**

|                                     |      |
|-------------------------------------|------|
| Degree of protection (EN IEC 60529) | IP65 |
|-------------------------------------|------|

**Device protection | Media**

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

**Mechanical data**

|              |      |
|--------------|------|
| Diameter LED | 5 mm |
|--------------|------|

**Mechanical data | Material data**

|                  |         |
|------------------|---------|
| Material housing | Plastic |
|------------------|---------|

**Mechanical data | Mounting data**

|                               |      |
|-------------------------------|------|
| Diameter front panel drilling | 9 mm |
|-------------------------------|------|

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
|----------------------------|--------|

|                            |       |
|----------------------------|-------|
| Operating temperature max. | 50 °C |
|----------------------------|-------|