

LED-INDICATOR OPAC / GREEN

LED-110V IP65

(green)

110 V AC/DC

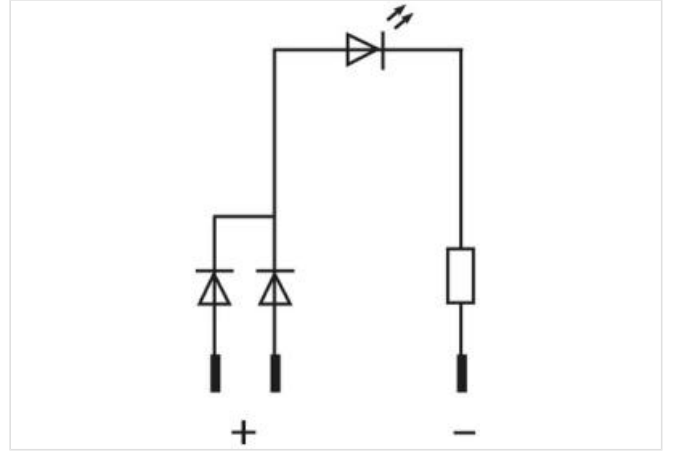
The modules are suitable for wall thickness of 1.5...5.0 mm.

Ürün Linki

örnekleme



Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
GTIN	4048879041263
Gümrük tarife no (gtip)	85318070
Paket miktarı	10

Electrical data | Supply

Operating voltage AC	110 V
Operating voltage AC min.	95 V
Operating voltage AC max.	121 V
Operating voltage DC	110 V
Operating voltage DC min.	95 V
Operating voltage DC max.	121 V
Current consumption min.	8 mA
Current consumption max.	12 mA

Installation | Connection

Connection information	Faston 2.8x0.8 mm
------------------------	-------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data

Diameter LED	5 mm
--------------	------

Mechanical data | Material data

Material housing	Plastic
------------------	---------

Mechanical data | Mounting data

Diameter front panel drilling	9 mm
-------------------------------	------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	50 °C
----------------------------	-------