



LED-display 230V AC blue

Product discontinued, no alternative

(blue)
230 V AC/DC
Protection IP40

Ürün Linki

örnekleme

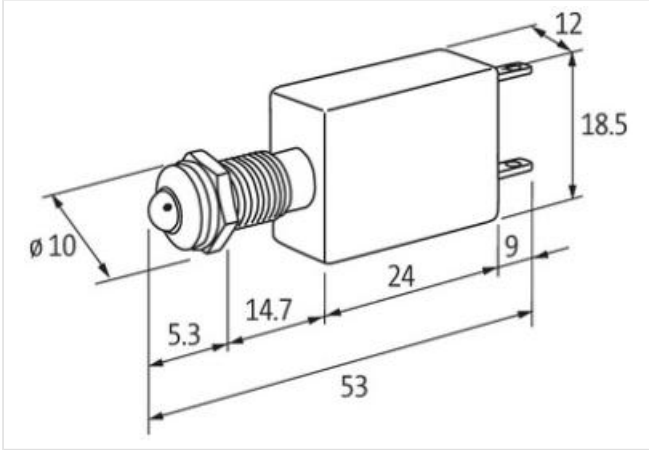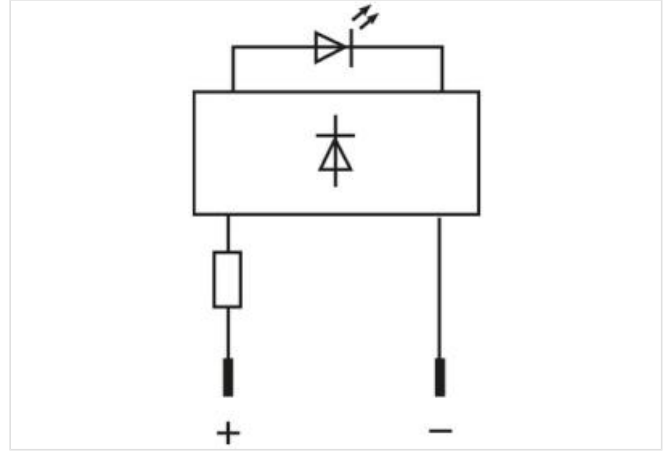

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27261590
ECLASS-7.0	27261590
ECLASS-8.0	27261590
ECLASS-9.0	27261590
ETIM-5.0	EC000272
GTIN	4048879040945
Gümrük tarife no (gtip)	85318070
Paket miktarı	10

Electrical data | Supply

Operating voltage AC	230 V
Operating voltage AC min.	207 V

Operating voltage AC max.	253 V
Current consumption min.	4,5 mA
Current consumption max.	5,5 mA
Installation Connection	
Connection information	Faston 2.8x0.8 mm
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP40
Mechanical data	
Diameter LED	5 mm
Mechanical data Material data	
Color housing	gray
Material housing	PVC
Mechanical data Mounting data	
Diameter front panel drilling	8 mm
Height	18,5 mm
Width	12 mm
Depth	53 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	70 °C