



LED-DISPLAY YELLOW 110V AC/DC IP67

Product discontinued, no alternative

(yellow)
110 V AC/DC
Protection IP67
with touch protection

Ürün Linki

örnekleme

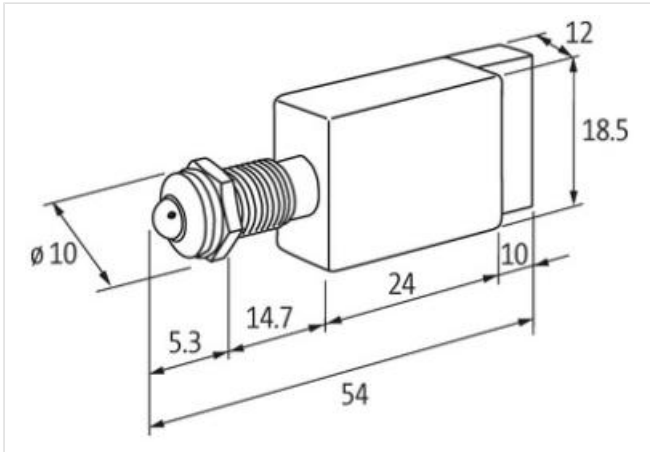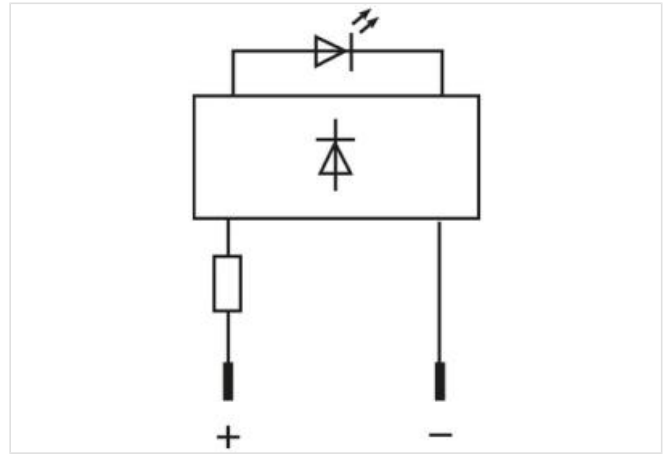

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27261590
ECLASS-7.0	27261590
ECLASS-8.0	27261590
ECLASS-9.0	27261590
ETIM-5.0	EC000272
GTIN	4048879040730
Gümrük tarife no (gtip)	85318070
Paket miktarı	10

Electrical data | Supply

Operating voltage AC	110 V
----------------------	-------

Operating voltage AC min.	95 V
Operating voltage AC max.	121 V
Operating voltage DC	110 V
Operating voltage DC min.	95 V
Operating voltage DC max.	121 V
Current consumption min.	4,5 mA
Current consumption max.	5,5 mA

Installation | Connection

Connection information	Faston 2.8x0.8 mm
------------------------	-------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
-------------------------------------	------

Mechanical data

Diameter LED	5 mm
--------------	------

Mechanical data | Material data

Color housing	gray
Material housing	PVC

Mechanical data | Mounting data

Diameter front panel drilling	8 mm
Height	18,5 mm
Width	12 mm
Depth	54 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	70 °C