



**LED-INDICATOR BLUE**

LED 5mm - 24V AC/DC - 15mA - IP67

(blue)  
24 V AC/DC  
Protection IP67

**Ürün Linki**

örnekleme

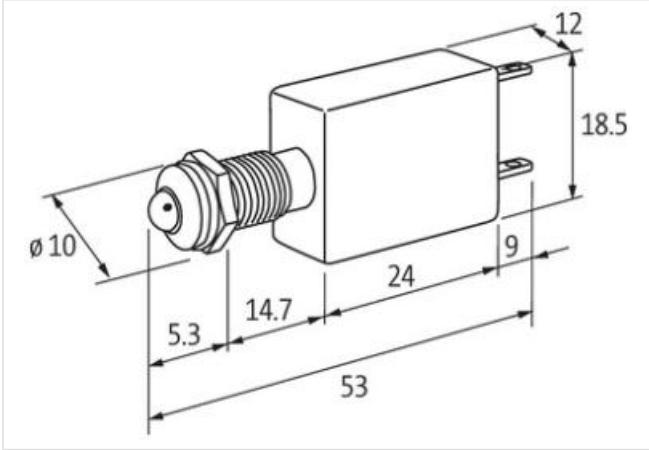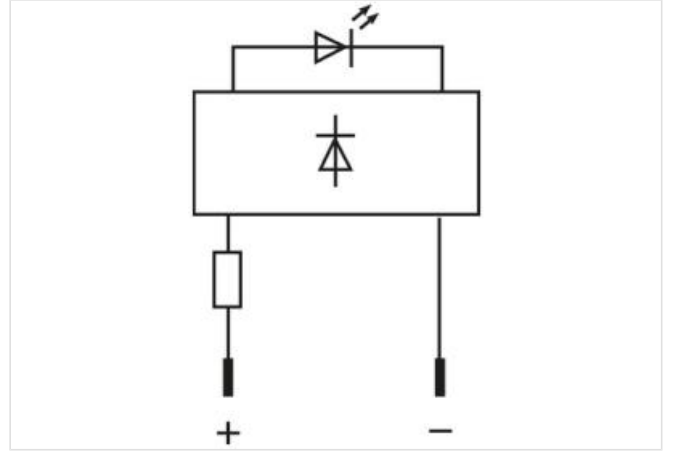

Ürün Image farklı olabilir

**Ticari bilgiler**

|                         |               |
|-------------------------|---------------|
| ECLASS-6.0              | 27261590      |
| ECLASS-6.1              | 27261501      |
| ECLASS-7.0              | 27261501      |
| ECLASS-8.0              | 27261501      |
| ECLASS-9.0              | 27261501      |
| ECLASS-10.1             | 27261501      |
| ECLASS-11.1             | 27261501      |
| ECLASS-12.0             | 27261501      |
| ETIM-5.0                | EC000272      |
| GTIN                    | 4048879040686 |
| Gümrük tarife no (gtip) | 85318070      |

Paket miktarı 10

**Electrical data | Supply**

|                           |        |
|---------------------------|--------|
| Operating voltage AC      | 24 V   |
| Operating voltage AC min. | 20,4 V |
| Operating voltage AC max. | 26,4 V |
| Operating voltage DC      | 24 V   |
| Operating voltage DC min. | 20,4 V |
| Operating voltage DC max. | 26,4 V |
| Current consumption min.  | 13 mA  |
| Current consumption max.  | 17 mA  |

**Installation | Connection**

Connection information Faston 2.8x0.8 mm

**Device protection | Electrical**

Degree of protection (EN IEC 60529) IP67

**Mechanical data**

Diameter LED 5 mm

**Mechanical data | Material data**

Color housing gray

Material housing PVC

**Mechanical data | Mounting data**

|                               |         |
|-------------------------------|---------|
| Diameter front panel drilling | 8 mm    |
| Height                        | 18,5 mm |
| Width                         | 12 mm   |
| Depth                         | 53 mm   |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -40 °C |
| Operating temperature max. | 70 °C  |