



LED-INDICATOR WHITE

LED 5mm - 24V AC/DC - 15mA - IP67

(white)
24 V AC/DC
Protection IP67

Ürün Linki

örnekleme

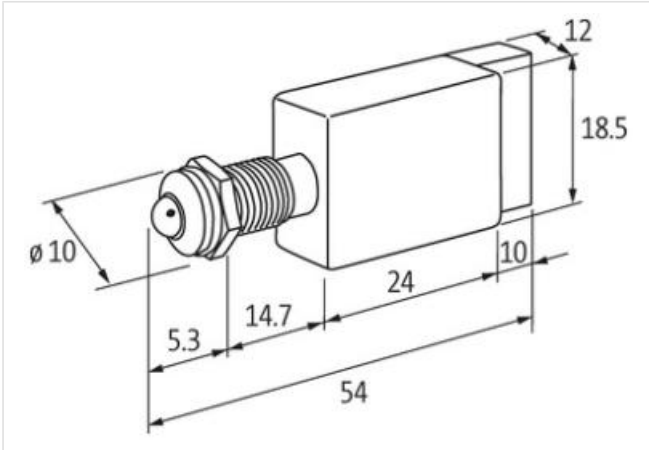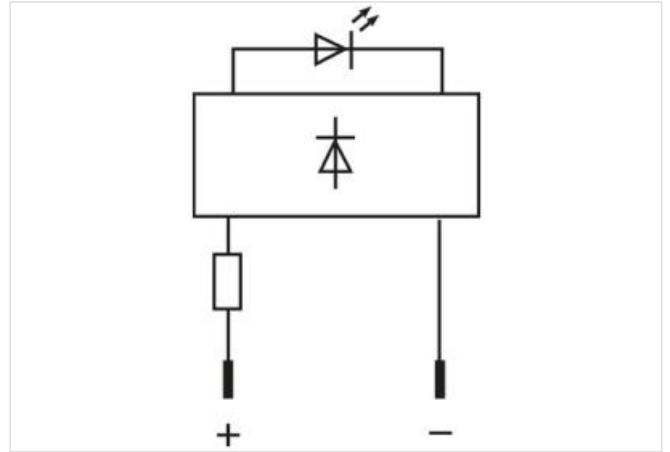

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
GTIN	4048879040655
Gümrük tarife no (gtip)	85318070

Paket miktarı 10

Electrical data | Supply

Operating voltage AC	24 V
Operating voltage AC min.	20,4 V
Operating voltage AC max.	26,4 V
Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption min.	13 mA
Current consumption max.	17 mA

Installation | Connection

Connection information Faston 2.8x0.8 mm

Device protection | Electrical

Degree of protection (EN IEC 60529) IP67

Mechanical data

Diameter LED 5 mm

Mechanical data | Material data

Color housing gray
Material housing PVC

Mechanical data | Mounting data

Diameter front panel drilling 8 mm
Height 18,5 mm
Width 12 mm
Depth 53 mm

Environmental characteristics | Climatic

Operating temperature min. -40 °C
Operating temperature max. 70 °C