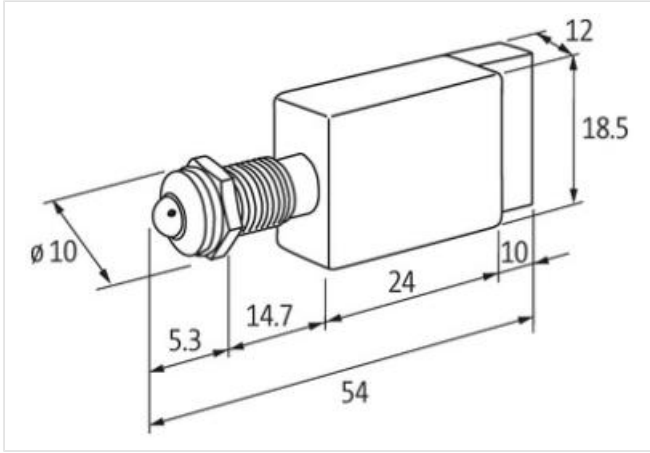
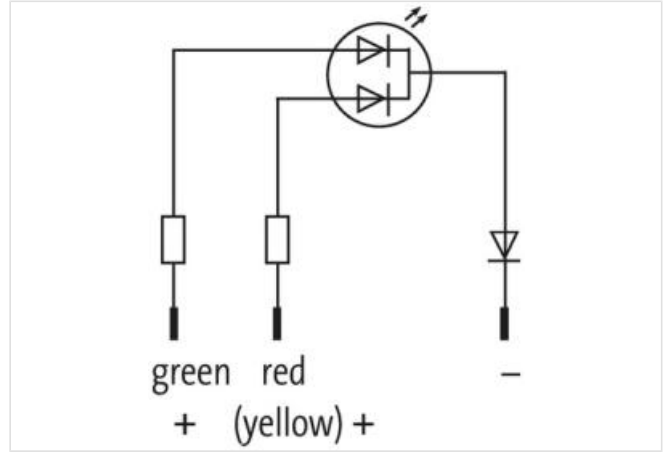


**LED-INDICATOR RED/GREEN**

LED 5mm - 24V DC - 15mA - IP67

(red/green)  
24 V DC  
Protection IP67  
with touch protection

**Ürün Linki****örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

|                         |               |
|-------------------------|---------------|
| ECLASS-6.0              | 27261590      |
| ECLASS-6.1              | 27261501      |
| ECLASS-7.0              | 27261501      |
| ECLASS-8.0              | 27261501      |
| ECLASS-9.0              | 27261501      |
| ECLASS-10.1             | 27261501      |
| ECLASS-11.1             | 27261501      |
| ECLASS-12.0             | 27261501      |
| ETIM-5.0                | EC000272      |
| GTIN                    | 4048879040556 |
| Gümrük tarife no (gtip) | 85318070      |

Paket miktarı 10

**Electrical data | Supply**

|                           |        |
|---------------------------|--------|
| Operating voltage DC      | 24 V   |
| Operating voltage DC min. | 20,4 V |
| Operating voltage DC max. | 26,4 V |
| Current consumption min.  | 13 mA  |
| Current consumption max.  | 17 mA  |

**Installation | Connection**

Connection information Faston 2.8x0.8 mm

**Device protection | Electrical**

Degree of protection (EN IEC 60529) IP67

**Mechanical data**

Diameter LED 5 mm

**Mechanical data | Material data**

Color housing gray  
Material housing PVC

**Mechanical data | Mounting data**

Diameter front panel drilling 8 mm  
Height 18,5 mm  
Width 12 mm  
Depth 54 mm

**Environmental characteristics | Climatic**

Operating temperature min. -40 °C  
Operating temperature max. 70 °C