



MTPS POWER SUPPLY 1/2-PHASE, SMOOTHED

IN: 230/400+/-15VAC OUT: :24V/2ADC

The MTPS series comprises single-/two-phase power supplies/rectified power supply units, incorporating safety isolating transformers, with protection class I and protection degree IP20 for general use in industrial applications.

Ürün Linki

örnekleme

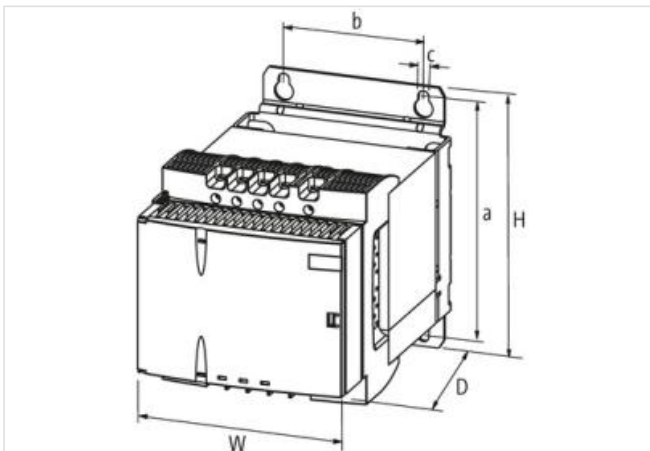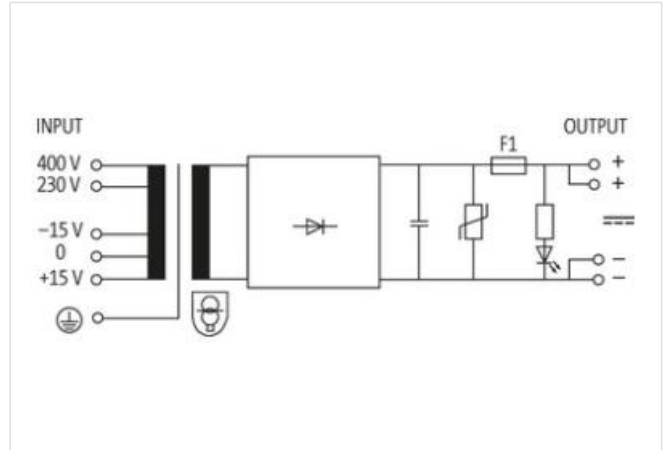

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27049002
ECLASS-7.0	27049002
ECLASS-8.0	27049002
ECLASS-9.0	27040701
ETIM-5.0	EC002540
GTIN	4048879079853
Gümrük tarife no (gtip)	85044095
Paket miktarı	1

Bu veri sayfasındaki bilgiler en büyük özenle hazırlandı.
Bilgilerin doğruluğu bütünlüğü ve güncelliği konusunda yükümlülük ihmalı sınırlıdır. Sürüm: 2024-05-04

Electrical data

Security level SELV

Electrical data | Supply

Power frequency 50 ... 60 Hz

Electrical data | Input

Fuse protection 1 primary side external 0,5 A @230 V AC

Fuse protection 2 primary side external 0,3 A @400 V AC

Characteristic back-up fuse Inertia

Input voltage 1 AC 230 V

Input voltage 1 AC min. 195,5 V

Input voltage 1 AC max. 264,5 V

Input voltage 2 AC 400 V

Input voltage 2 AC min. 340 V

Input voltage 2 AC max. 460 V

Input current at input voltage 1 AC 0,37 A

Input current at input voltage 2 AC 0,21 A

Electrical data | Output

Fuse protection secondary side external 2 A

Output suppression LED, Screening capacitor, VDR

Output voltage DC 24 V

Output voltage adjustable no

Output current max. 2 A

Characteristic secondary fuse Inertia

Ripple max. 5 %

Diagnostics

Status indication LED green

Mechanical data | Mounting data

Mounting method geschnappt

Suitable for mounting type Tragschiene TH35-15, Schlüssellochabhängung, (EN 60715)

Mounting dimension a 96 mm

Mounting dimension b 60 mm

Mounting dimension c 5,5 mm

Height 108 mm

Width 87 mm

Depth 142 mm

Environmental characteristics | Climatic

Operating temperature min. -20 °C

Operating temperature max. 60 °C

Conformity

Product standard EN 61558-2-6, EN 62041 category I

EMC EN 55011 B, EN 61000-3-2

Connection type 2

Connection type 1 Input

Connection type 2 Output

Connection Screw terminals SK

Family construction form terminal

Gender female

No. of poles 5

PIN 1 + 15 V

PIN 3 - 15 V

PIN 4 230 V

PIN 5	400 V
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	5
PIN 1	PE
PIN 2	-
PIN 3	-
PIN 4	+
PIN 5	+