



MASI ASI POWER SUPPLY 1-PHASE,

IN: 230VAC OUT: 30,5V/2,8ADC

INPUT: 230 V AC
Current: 2.8 A
Single-phase, primary switched
Protection IP20
Unit complies to AS-Interface specification for power supplies (PELV)

Ürün Linki

örnekleme

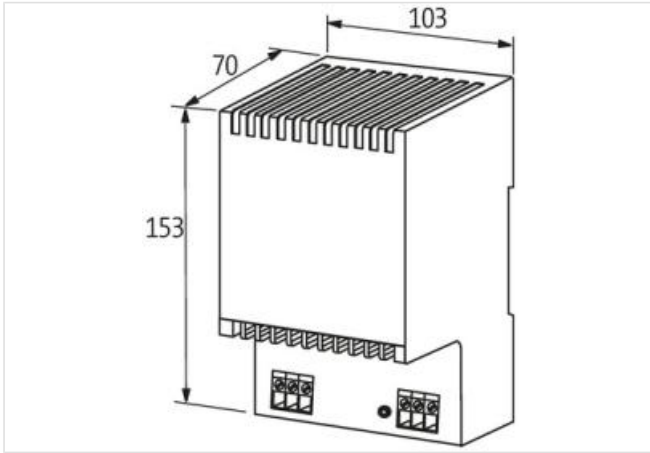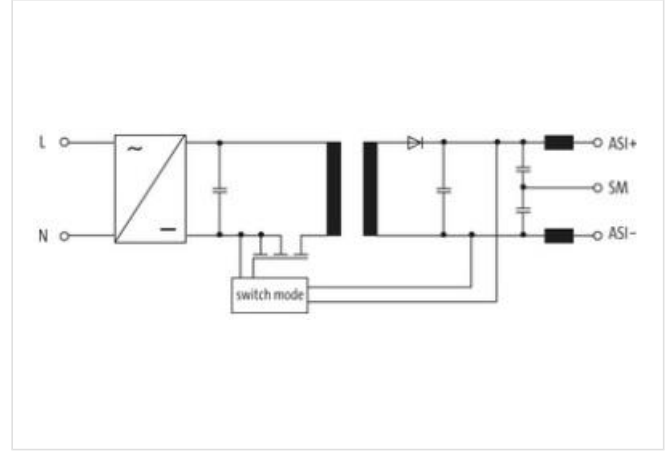

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27049002
ECLASS-7.0	27049002
ECLASS-8.0	27049002
ECLASS-9.0	27040701
ETIM-5.0	EC002540

GTIN 4048879079815

Gümrük tarife no (gtip) 85044095

Paket miktarı 1

Electrical data

Security level SELV

Electrical data | Supply

Power frequency 50 ... 60 Hz

Electrical data | Input

Characteristic back-up fuse Inertia

Input voltage 1 AC 230 V

Current input AC 0,8 A

Inrush current max. 20 A

External back-up fuse per phase max. 10 A

Efficiency 85 %

Electrical data | Output

Output suppression Filter acc. to AS-Interface specification

Output rating 85,4 W

Output voltage DC 30,5 V

Output voltage DC min. 29,58 V

Output voltage DC max. 31,42 V

Output voltage adjustable no

Output current max. 2,8 A

Mains failure bridging min. 30 ms @ 230 V AC

Ripple (s-s) max. 50 mV

Device protection | Electrical

Degree of protection (EN IEC 60529) IP20

Overload protection output yes

Short-circuit protection output yes

Mechanical data | Mounting data

Mounting method geschnappt

Suitable for mounting type Mounting rail TH35, (EN 60715)

Environmental characteristics | Climatic

Operating temperature min. -10 °C

Operating temperature max. 60 °C

Conformity

Product standard IEC 61010-2-201

EMC EN 55022 B

Low Voltage Directive EN 61204-3