



NG 10 RECTIFIER UNIT 1-PHASE

IN: 29VAC OUT: 24V/10A

Rectifiers, single phase
INPUT: 29 V AC
OUTPUT: 24 V DC
Output rating: 240 W
Current: max. 10 A

Ürün Linki

örnekleme

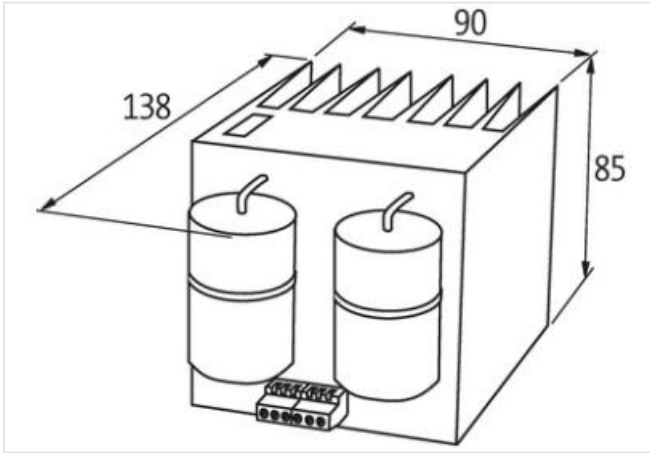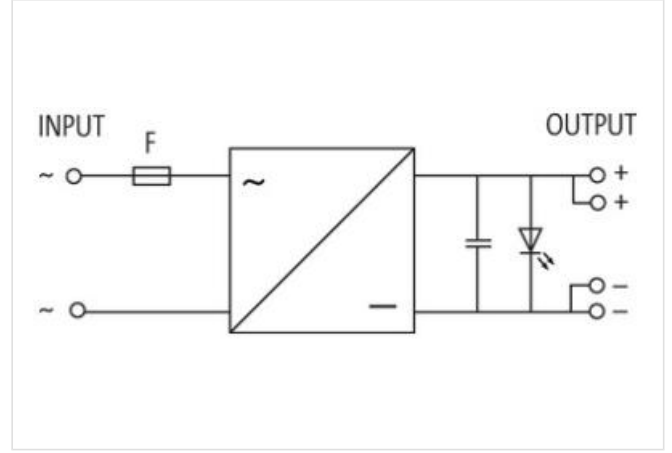

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27049002
ECLASS-6.1	27040390
ECLASS-7.0	27040390
ECLASS-8.0	27040390
ECLASS-9.0	27040390

ECLASS-10.1	27040390
ECLASS-11.1	27040390
ECLASS-12.0	27040390
ETIM-5.0	EC002540
GTIN	4048879079471
Gümrük tarife no (gtip)	85044083
Paket miktarı	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Fuse protection primary side internal	16 A
Type of primary fuse	Microfuse 5 × 20 mm
Characteristic back-up fuse	Mittelträge
Input voltage 1 AC	29 V
Input current DC max.	10 A

Electrical data | Output

Output suppression	LED, screened with electrolytic capacitor
Output voltage DC max.	39 V
Output voltage adjustable	no
Output current max.	10 A
Ripple max.	5 %

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 2

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	2
PIN 1	AC
PIN 2	AC
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	4
PIN 1	-
PIN 2	-
PIN 3	+
PIN 4	+